


## Xenterra 8TX unmanaged Switch wallmounted 8 Port 100Mbit WM

8 port unmanaged switch  
Key-hole mounting/screwable  
Connection cables are in the online shop under "Connection Technology".

### [Link to Product](#)

#### Illustration

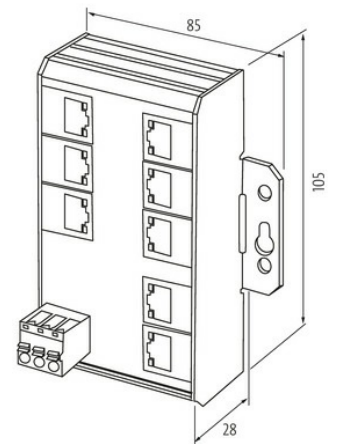

Product may differ from Image

#### Approvals



#### More Info

Bus technologies

#### Technical Data

Operating voltage	8...28 V AC/9...36 V DC
Transfer rate	10/100 Mbit/s full duplex
Operating modes	Autocrossing Autonegotiation

#### General data

The information in this brochure has been compiled with the utmost care.  
Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 05/21

Mounting method	Key-hole mounting/screwable
Temperature range	-40...+70 °C (storage temperature -40...+85 °C)
Housing	Metal black
Protection	IP20
Dimensions H×W×D	105×85×28 mm

#### Connections

Fieldbus	8× RJ45
Supply	Push-In spring clamp terminals, 0.2...2.5 mm <sup>2</sup> (0.25...1.5 mm <sup>2</sup> )

#### Switch Management

Protocols	no
Port Mirroring	no
VLAN (QoS) IEEE 802.p	yes
Alarm contact	no
Remote maintenance	no
Webserver	no
Switch Form	Unmanaged Switch

#### Diagnostic

Communication status	via LED
Monitoring - no voltage	yes

#### Commercial data

country of origin	DE
customs tariff number	85176200
EAN	4048879830409
eClass	19170106
Packaging unit	1.000