



MST 1-PHASE CONTROL AND ISOLATION TRANSFORMER

P: 500VA IN: 230/400VAC OUT: 230VAC

Single-phase - Control and Isolation Transformers
500 VA
Isolation class T 40/B
Other voltages on request.

[Link to Product](#)

Illustration

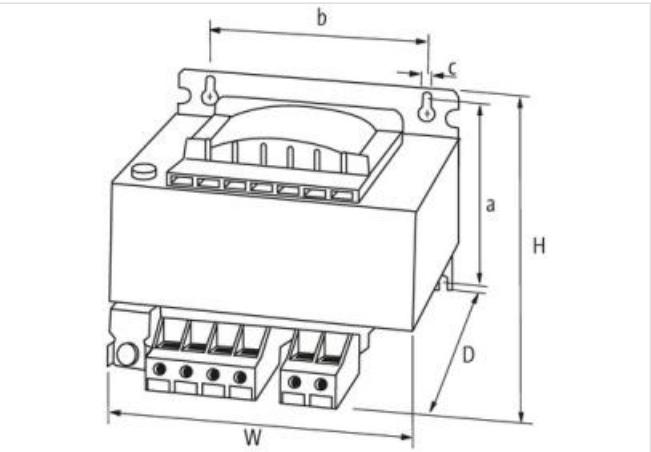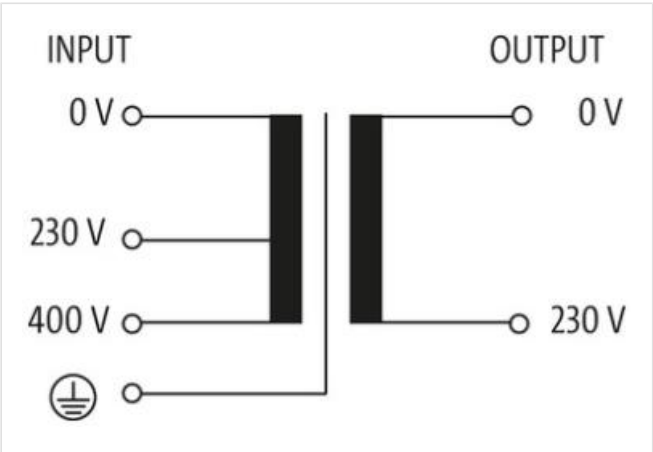

Product may differ from Image



Commercial data	
ECLASS-6.0	27031302
ECLASS-6.1	27031302
ECLASS-7.0	27031302
ECLASS-8.0	27031302
ECLASS-9.0	27031302
ECLASS-10.1	27031302

ECLASS-11.1	27031302
ECLASS-12.0	27031302
ETIM-5.0	EC002486
customs tariff number	85043180
GTIN	4048879078658
Packaging unit	1
Electrical data Supply	
Power frequency	50 ... 60 Hz
Electrical data Input	
Input voltage 1 AC	230 V
Input voltage 2 AC	400 V
Input current at input voltage 1 AC	2,4 A
Input current at input voltage 2 AC	1,4 A
Inrush current at input voltage 1	28,1 A
Inrush current at input voltage 2	16,3 A
Short-circuit current at input voltage 1	54 A
Short-circuit current at input voltage 2	31,2 A
Electrical data Output	
Output voltage AC	230 V
Output voltage adjustable	no
Power rating AC max.	500 VA
Device protection Electrical	
Insulation test voltage input - output	4 kV
Mechanical data Mounting data	
Suitable for mounting type	Schlüssellochaufhängung
Mounting dimension a	87 mm
Mounting dimension b	104 mm
Mounting dimension c	5,8 mm
Height	108 mm
Width	135 mm
Depth	133,6 mm
Diameter bore	5,8 mm
Length bore	10 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	40 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C
Conformity	
Product standard	EN 61558-1, EN 61558-2-4, EN 62041 category 0