



M12 DC/DC-TRANSFORMER

IN: 24 VDC - OUT: 10 VDC / 25 mA


Voltage regulator
12...30 V DC/ 10 V DC

[Link to Product](#)

Illustration

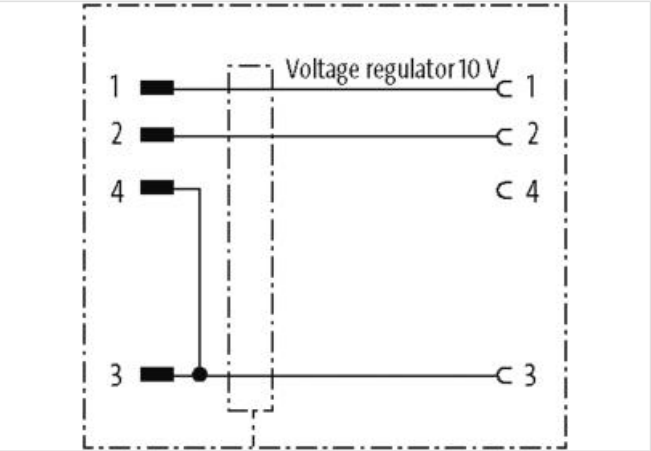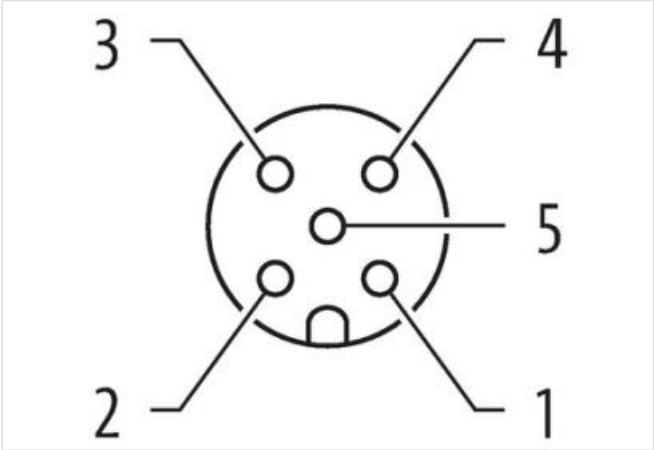

Product may differ from Image

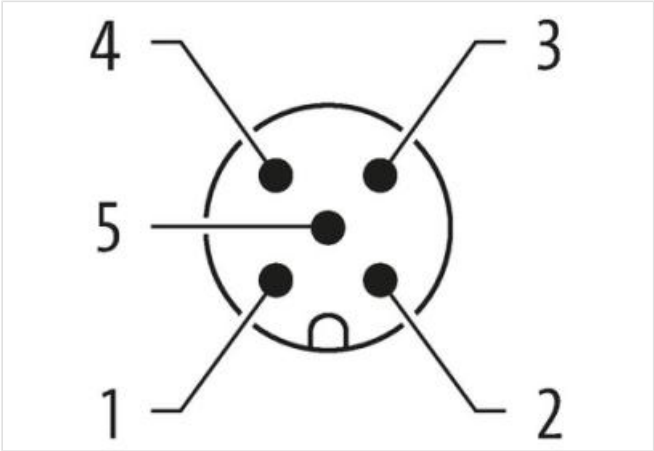

Commercial data	
ECLASS-6.0	27049002
ECLASS-6.1	27210901
ECLASS-7.0	27210901
ECLASS-8.0	27210901
ECLASS-9.0	27210901
ECLASS-10.1	27210901
ECLASS-11.1	27210901
ECLASS-12.0	27210901

ETIM-5.0	EC002540
customs tariff number	85043121
GTIN	4048879025065
Packaging unit	1
Electrical data Input	
Input voltage DC	24 V
Input voltage DC min.	12 V
Input voltage DC max.	30 V
Input current	3 mA
Electrical data Output	
Output voltage DC	10 V
Output voltage adjustable	no
Output current per channel max.	0,025 A
Installation Connection	
Family construction form	M12
Device protection Electrical	
Short-circuit protected	yes
Mechanical data Mounting data	
Height	24,5 mm
Width	24,5 mm
Depth	60,5 mm