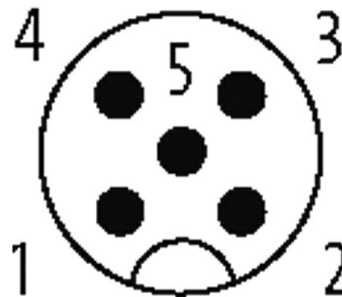


M12 MALE 0° SHIELDED WIREABLE SCREW TERM.5-pol. max.0,75mm² 4-6mm

Male straight
M12, 5-pole
shielded
Screw terminals
Sealing range (cable Ø): 4...6 mm

[Link to Product](#)**Illustration**

Male



Product may differ from Image

Form

Form 13301

Technical Data

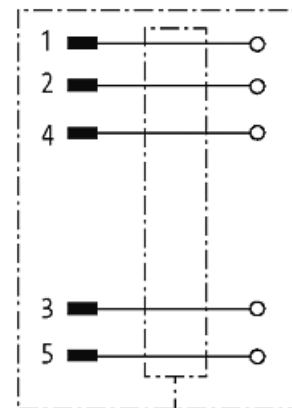
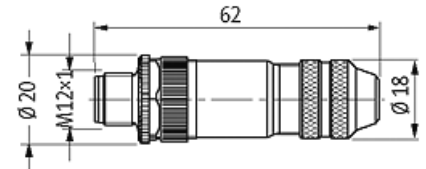
Operating voltage	max. 60 V AC/DC
Operating current per contact	max. 4 A
Connection cross section	max. 0.75 mm ²
Sealing range (cable Ø)	4...6 mm
Protection	IP67 inserted and tightened (EN 60529)
Housing	Brass, nickel plated

General data

Temperature range -40...+85 °C

Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879198844
eClass	27279221
Packaging unit	1

Sketch

Product may differ from Image