


EXACT8, 4XM8, 3 POLE MOULDED CABLE

5.0m PUR 4*0,34+2*0,75 exit norm..



5.0 m

[Link to Product](#)


Illustration

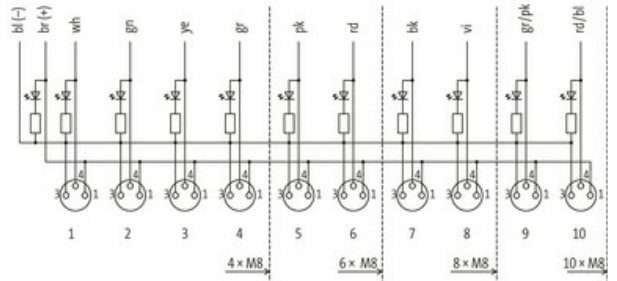

M8-Females 3-pole

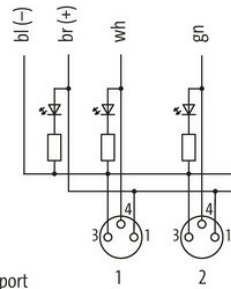 

for 1 signal per port

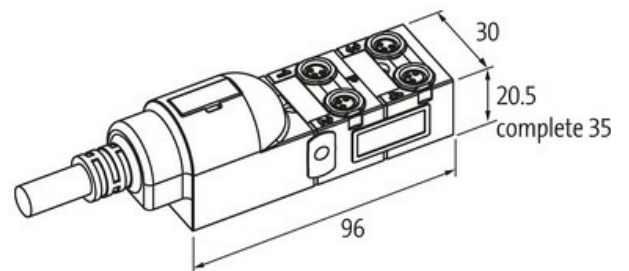

Product may differ from Image

Approvals

The information in this brochure has been compiled with the utmost care. Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 05/21



More Info

Bus technologies

Form

Form 84010

Technical Data

Operating voltage	24 V DC
Operating current per contact	max. 2 A
Locking of ports	Screw thread (M8x1 mm)
Protection	IP65/IP67
Housing	Plastic, flame retardant
Signal per port	1 - (31-32)
Total current	max. 8 A

General data

Temperature range -20...+80 °C, depending on cable quality

Cables

No./diameter of wires	4x 0.34 + 2x 0.75 mm ²
Wire isolation	TPE-E
C-track properties	5 Mio.
Outer Ø	7.6 mm ±5%
Cable number	334
Approval (cable)	UL (AWM-Style 20233), CSA
Color (jacket)	gray
Jacket Color	gray
Temperature range (fixed)	-40...+80 °C
Temperature range (mobile)	-5...+60 °C
Bend radius (fixed)	5x outer Ø
Bend radius (moving)	10x outer Ø
Material (jacket)	PUR (UL/CSA)

Contact Layout

PIN 1	(+)
PIN 3	(-)
PIN 4	(NO)/(S1)
	LED (green): Power / LED (yellow): (S1)

Commercial data

country of origin	DE
customs tariff number	85444290
EAN	4048879056571
eClass	27279219
Packaging unit	1.000