

**SIEMENS CONTACTOR SUPPRESSOR**

RC, 230VAC/DC



230 V AC/DC

RC

For other configurations and voltages, please inquire.

[Link to Product](#)

Illustration

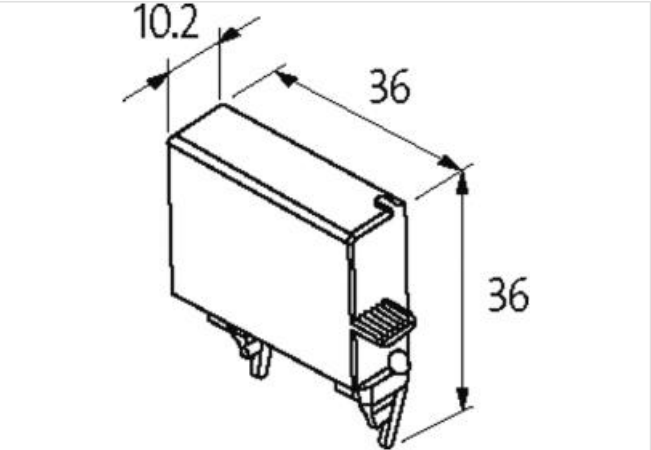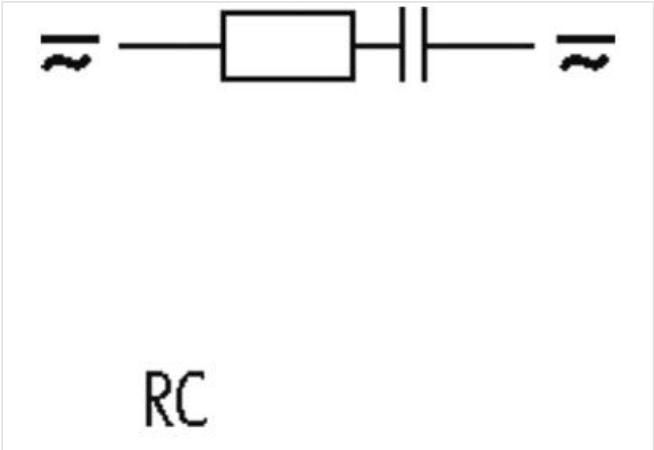

Product may differ from Image



| Commercial data |          |
|-----------------|----------|
| ECLASS-6.0      | 27371013 |
| ECLASS-6.1      | 27371013 |
| ECLASS-7.0      | 27371013 |
| ECLASS-8.0      | 27371013 |
| ECLASS-9.0      | 27371013 |
| ECLASS-10.1     | 27371013 |

|                                                 |                 |
|-------------------------------------------------|-----------------|
| ECLASS-11.1                                     | 27371013        |
| ECLASS-12.0                                     | 27371013        |
| ETIM-5.0                                        | EC002498        |
| customs tariff number                           | 85363010        |
| GTIN                                            | 4048879019910   |
| Packaging unit                                  | 1               |
| <b>Compatibility   Compatible with</b>          |                 |
| Appropriate contactors                          | 3 RT 1.3/1.4    |
| <b>Electrical data</b>                          |                 |
| Damping factor                                  | 1.5× UN         |
| <b>Electrical data   Input</b>                  |                 |
| Input voltage AC min.                           | 127 V           |
| Input voltage AC max.                           | 250 V           |
| Input voltage DC min.                           | 127 V           |
| Input voltage DC max.                           | 250 V           |
| <b>Installation   Connection</b>                |                 |
| Connection information                          | Plug contact    |
| <b>Device protection   Media</b>                |                 |
| Flame resistance                                | flame retardant |
| <b>Mechanical data   Material data</b>          |                 |
| Combustibility class housing (UL94)             | V-0             |
| Material housing                                | Plastic         |
| <b>Mechanical data   Mounting data</b>          |                 |
| Height                                          | 36 mm           |
| Width                                           | 36 mm           |
| Depth                                           | 10,2 mm         |
| <b>Environmental characteristics   Climatic</b> |                 |
| Operating temperature min.                      | -20 °C          |
| Operating temperature max.                      | 70 °C           |