

SUPPRESSOR FOR CONTACTORS

Diode, 24....240 VDC, 50 W


24...240 V DC

Diode

For other configurations and voltages, please inquire.

[Link to Product](#)

Illustration

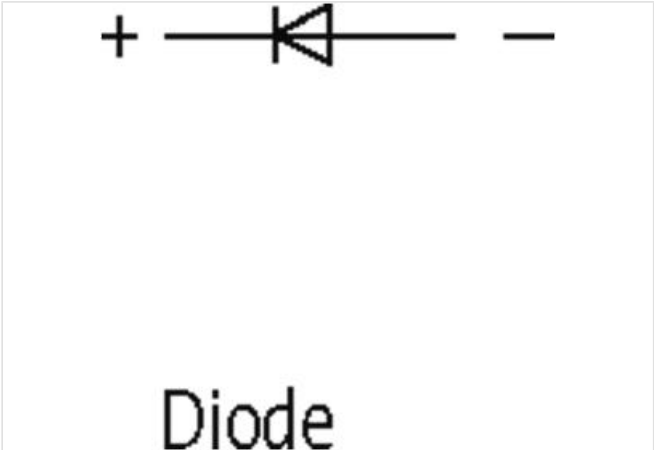

Product may differ from Image



Commercial data	
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013

ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC002498
customs tariff number	85363010
GTIN	4048879018647
Packaging unit	1
Compatibility Compatible with	
Appropriate contactors	universal
Electrical data	
Holding power max.	50 W
Electrical data Input	
Input voltage DC min.	24 V
Input voltage DC max.	240 V
Mechanical data Mounting data	
Height	20 mm
Width	43 mm
Depth	12 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	70 °C