



MOELLER CONTACTOR SUPPRESSOR

Varistor, 230VAC/DC

230 V AC/DC  
VDR  
For other configurations and voltages, please inquire.

[Link to Product](#)

Illustration

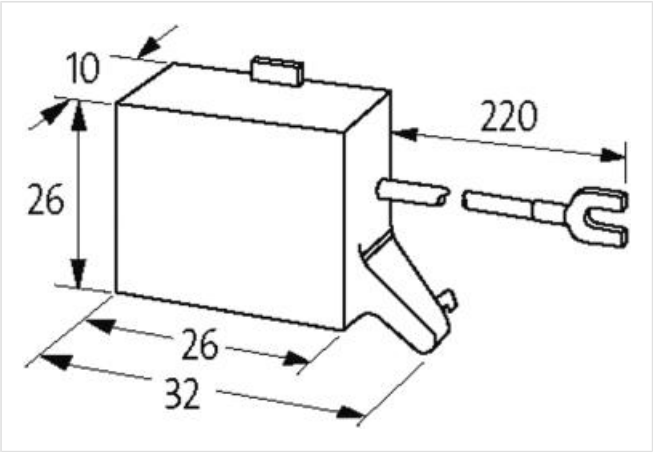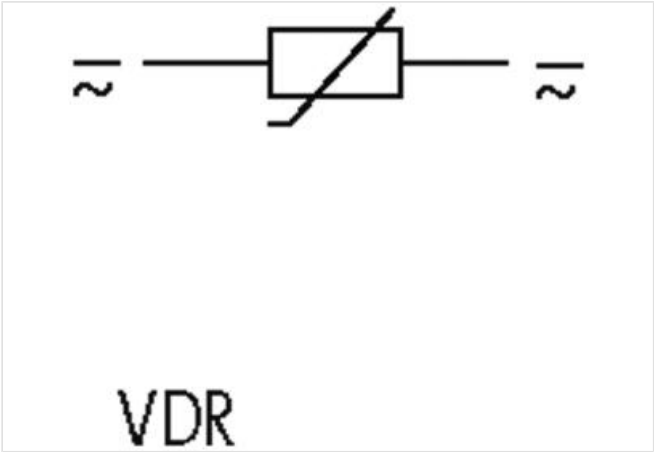

Product may differ from Image



| Commercial data |          |
|-----------------|----------|
| ECLASS-6.0      | 27371013 |
| ECLASS-6.1      | 27371013 |
| ECLASS-7.0      | 27371013 |
| ECLASS-8.0      | 27371013 |
| ECLASS-9.0      | 27371013 |
| ECLASS-10.1     | 27371013 |

|                       |               |
|-----------------------|---------------|
| ECLASS-11.1           | 27371013      |
| ECLASS-12.0           | 27371013      |
| ETIM-5.0              | EC002498      |
| customs tariff number | 85363010      |
| GTIN                  | 4048879018388 |
| Packaging unit        | 1             |

**Compatibility | Compatible with**

|                        |           |
|------------------------|-----------|
| Appropriate contactors | DIL E...C |
|------------------------|-----------|

**Electrical data**

|                |         |
|----------------|---------|
| Damping factor | 1.5× UN |
|----------------|---------|

**Electrical data | Input**

|                       |       |
|-----------------------|-------|
| Input voltage AC min. | 110 V |
| Input voltage AC max. | 250 V |
| Input voltage DC min. | 110 V |
| Input voltage DC max. | 250 V |

**Installation | Connection**

|                        |                           |
|------------------------|---------------------------|
| Connection information | self-securing cable forks |
|------------------------|---------------------------|

**Device protection | Media**

|                  |                 |
|------------------|-----------------|
| Flame resistance | flame retardant |
|------------------|-----------------|

**Mechanical data | Material data**

|                                     |         |
|-------------------------------------|---------|
| Combustibility class housing (UL94) | V-0     |
| Material housing                    | Plastic |

**Mechanical data | Mounting data**

|        |         |
|--------|---------|
| Height | 27,5 mm |
| Width  | 10 mm   |
| Depth  | 32 mm   |

**Environmental characteristics | Climatic**

|                            |        |
|----------------------------|--------|
| Operating temperature min. | -20 °C |
| Operating temperature max. | 70 °C  |