

ABB CONTACTOR SUPPRESSOR

Varistor, 48VDC


48 V AC/DC

VDR

For other configurations and voltages, please inquire.

[Link to Product](#)

Illustration

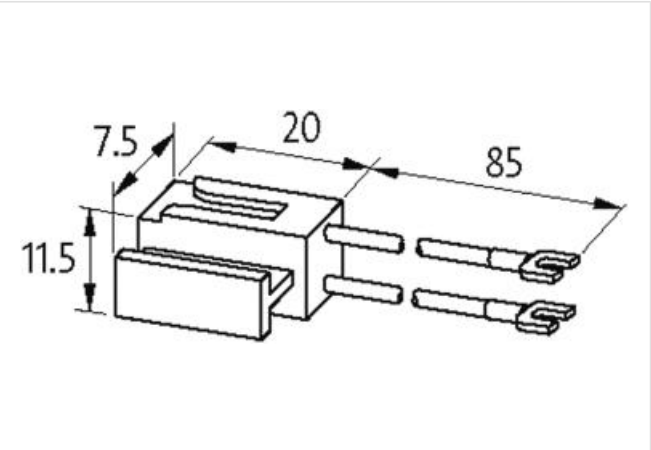

Product may differ from Image



Commercial data	
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013

ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC002498
customs tariff number	85363010
GTIN	4048879018050
Packaging unit	1

Compatibility | Compatible with

Appropriate contactors	B 6, BC 6, KC 6, VB 6
------------------------	-----------------------

Electrical data

Damping factor	1.5× UN
----------------	---------

Electrical data | Input

Input voltage AC min.	24 V
Input voltage AC max.	53 V
Input voltage DC min.	24 V
Input voltage DC max.	53 V

Installation | Connection

Connection information	self-securing cable forks
------------------------	---------------------------

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Combustibility class housing (UL94)	V-0
Material housing	Plastic

Mechanical data | Mounting data

Height	20 mm
Width	11,5 mm
Depth	7,5 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C