



ALLEN-BRADLEY CONTACTOR SUPPRESSOR

Varistor, 24VAC/DC

24 V AC/DC
VDR
For other configurations and voltages, please inquire.

Link to Product

Illustration

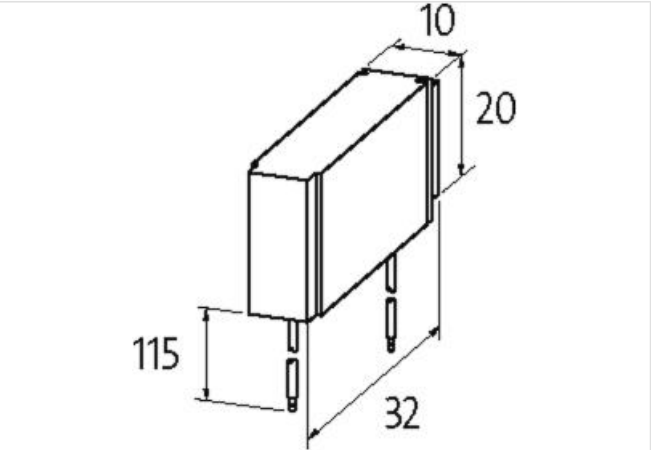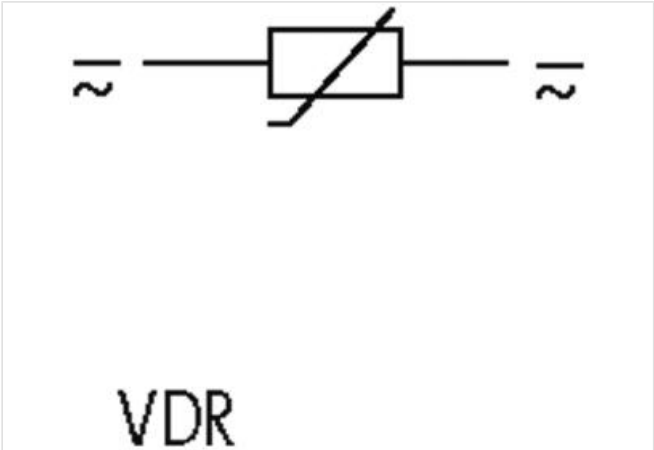

Product may differ from Image



Commercial data	
ECLASS-6.0	27371013
customs tariff number	85363010
GTIN	4048879017848
Packaging unit	1
Compatibility Compatible with	
Appropriate contactors	100-M
Electrical data	

Damping factor	1.5× UN
----------------	---------

Electrical data | Input

Input voltage AC min.	24 V
-----------------------	------

Input voltage AC max.	30 V
-----------------------	------

Input voltage DC min.	24 V
-----------------------	------

Input voltage DC max.	30 V
-----------------------	------

Installation | Connection

Connection information	flexible connection wires
------------------------	---------------------------

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Combustibility class housing (UL94)	V-0
-------------------------------------	-----

Material housing	Plastic
------------------	---------

Mechanical data | Mounting data

Height	20 mm
--------	-------

Width	10 mm
-------	-------

Depth	32 mm
-------	-------

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
----------------------------	--------

Operating temperature max.	70 °C
----------------------------	-------