



POWER DISTRIBUTOR PD4 7/8" 5 POLE

24+E male to 4 x 7/8" 5-pole female

Industry male plug 24+PE  
to 4x 7/8" UNF female  
5-pole

[Link to Product](#)

Illustration

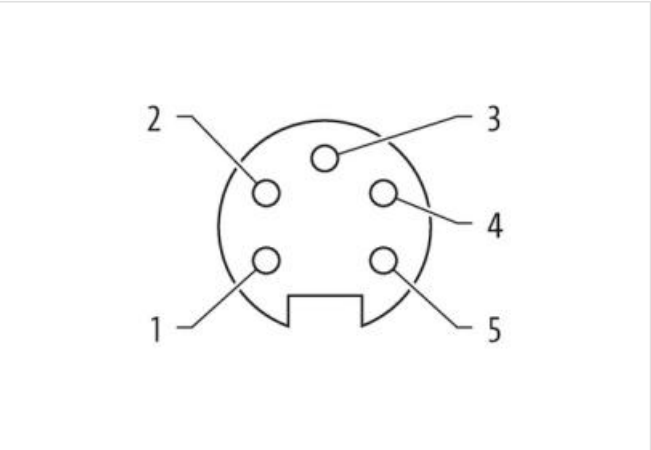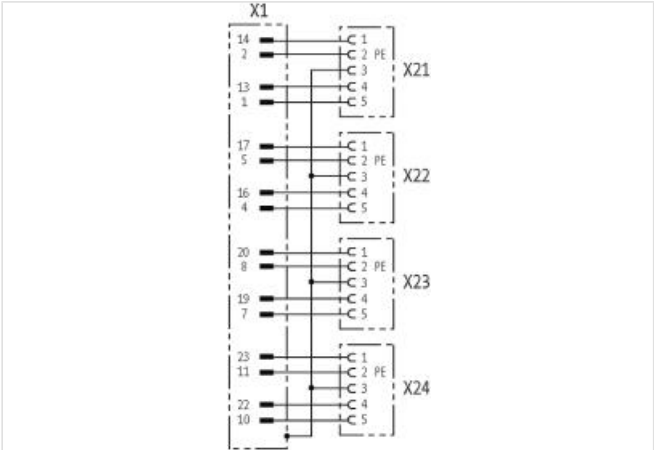

Product may differ from Image



Commercial data	
ECLASS-6.0	27279219
ECLASS-6.1	27142601
ECLASS-7.0	27142601
ECLASS-8.0	27142601
ECLASS-9.0	27142601
ECLASS-10.1	27142601

ECLASS-11.1	27142606
ECLASS-12.0	27142606
ETIM-5.0	EC002585
customs tariff number	85369010
GTIN	4048879063449
Packaging unit	1
<b>Electrical data</b>	
Security level	SELV
<b>Electrical data   Supply</b>	
Operating voltage AC	50 V
Operating voltage DC	120 V
Current operating per contact max.	9 A
<b>Device protection   Electrical</b>	
Degree of protection (EN IEC 60529)	IP67
Additional condition protection degree	inserted, screwed
<b>Mechanical data   Material data</b>	
Coating housing	powder-coated
Material housing	Aluminum die casting
<b>Mechanical data   Mounting data</b>	
Height	165 mm
Width	70 mm
Depth	100 mm
Looking techniques	2-hand fixing (2 clamps)
<b>Environmental characteristics   Climatic</b>	
Operating temperature min.	-30 °C
Operating temperature max.	85 °C