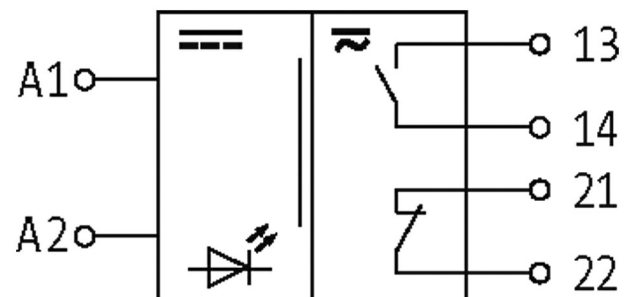
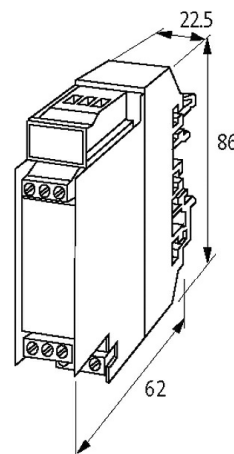


**MKS-RM 111/24V**

1 relay; 1 NO contact/1 NC contact  
 6 A  
 24 V DC  
 with force guided contacts  
 Screw terminals

[Link to Product](#)**Illustration**

Product may differ from Image

**General data**

Mech./ elect. life 10 000 000 switching cycles/load dependent

The information in this brochure has been compiled with the utmost care.  
 Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 05/21

Test isolation voltage	4.0 kV
Mounting method	DIN-rail mountable TH35 or G32 (EN 60715)
Temperature range	-20...+50 °C
Dimensions H×W×D	86×22.5×62 mm

#### Output

Switching voltage	max. 250 V AC/DC
Switching current per output	max. 6 A
Min. load current	10 mA
Power rating (voltage dependent)	max. 1500 VA/100 W
Switching frequency	max. 5 Hz
Contact material	Ag Ni 10 hv
Energize/release/contact bounce time	15/15/1.5 ms

#### Input

Connection voltage - current	24 V AC/DC (21.6...28 V AC/DC) - 38 mA
LED display	LED (green)

#### Utilization category

AC-1	6 A (24/110/230 V AC)
AC-15	3 A (24/110/230 V AC)
DC-13	3 A (24 V DC); 0.22 A (110 V DC); 0.1 A (230 V DC)

#### Commercial data

country of origin	CZ
customs tariff number	85364900
EAN	4048879027670
eClass	27371001
Packaging unit	1