



MIRO TR 90-250VAC SK OPTO-COUPLER MODULE

IN: 250 VAC - OUT: 48 VDC / 2 A

Transistor 2 A  
230 V AC  
Screw terminals

[Link to Product](#)

Illustration

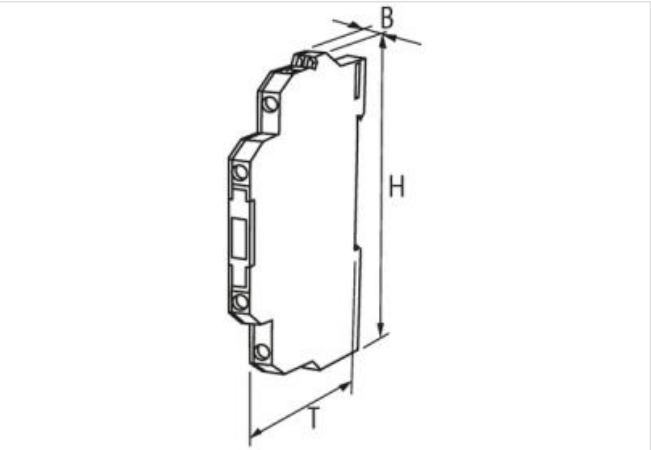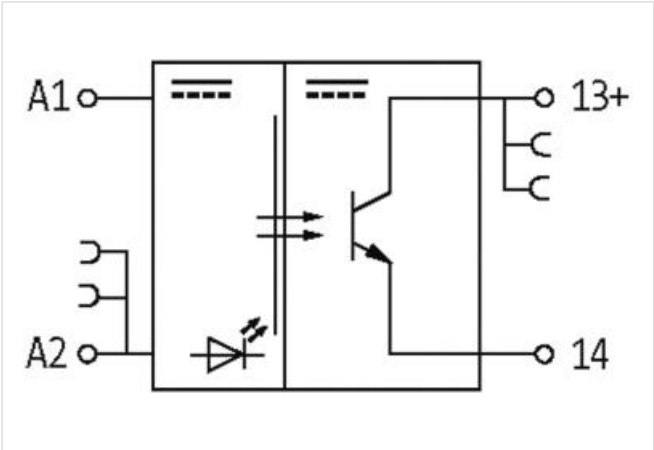

Product may differ from Image



| Commercial data |          |
|-----------------|----------|
| ECLASS-6.0      | 27371604 |
| ECLASS-6.1      | 27371604 |
| ECLASS-7.0      | 27371604 |
| ECLASS-8.0      | 27371604 |
| ECLASS-9.0      | 27371604 |
| ECLASS-10.1     | 27371604 |

|                       |               |
|-----------------------|---------------|
| ECLASS-11.1           | 27371604      |
| ECLASS-12.0           | 27371604      |
| ETIM-5.0              | EC001504      |
| customs tariff number | 85414900      |
| GTIN                  | 4048879026871 |
| Packaging unit        | 1             |

**Electrical data | Input**

|                           |       |
|---------------------------|-------|
| Input voltage AC min.     | 90 V  |
| Input voltage AC max.     | 250 V |
| Input voltage OFF AC min. | 0 V   |
| Input voltage OFF AC max. | 30 V  |
| Current input AC          | 15 mA |

**Electrical data | Output**

|                                    |        |
|------------------------------------|--------|
| Switch off delay max.              | 10 ms  |
| Switch on delay max.               | 3 ms   |
| Quiescent current OFF max.         | 0,3 mA |
| Switching frequency inductive max. | 1 Hz   |
| Switching frequency ohmic max.     | 10 Hz  |
| Voltage switching DC min.          | 5 V    |
| Switching voltage DC max.          | 48 V   |
| Switching current min.             | 1 mA   |
| Switching current max.             | 2 A    |
| Voltage drop DC max.               | 0,3 V  |

**Diagnostics**

|                       |        |
|-----------------------|--------|
| Status indication LED | yellow |
|-----------------------|--------|

**Device protection | Electrical**

|                     |        |
|---------------------|--------|
| Rated surge voltage | 2,5 kV |
|---------------------|--------|

**Device protection | Media**

|                  |                 |
|------------------|-----------------|
| Flame resistance | flame retardant |
|------------------|-----------------|

**Mechanical data | Material data**

|                  |         |
|------------------|---------|
| Color housing    | black   |
| Material housing | Plastic |

**Mechanical data | Mounting data**

|                            |                           |
|----------------------------|---------------------------|
| Mounting method            | geschnappt                |
| Suitable for mounting type | mounting rail, (EN 60715) |
| Height                     | 78 mm                     |
| Width                      | 6,2 mm                    |
| Depth                      | 70 mm                     |

**Environmental characteristics | Climatic**

|                            |        |
|----------------------------|--------|
| Operating temperature min. | -20 °C |
| Operating temperature max. | 60 °C  |

**Connection type 4**

|                          |                    |
|--------------------------|--------------------|
| Connection               | Screw terminals SK |
| Family construction form | terminal           |
| Gender                   | female             |
| Color contact carrier    | green              |
| No. of poles             | 1                  |
| PIN 1                    | 13 +               |
| Connection               | Screw terminals SK |
| Family construction form | terminal           |
| Gender                   | female             |

|                          |                    |
|--------------------------|--------------------|
| Color contact carrier    | green              |
| No. of poles             | 1                  |
| PIN 1                    | 14                 |
| Connection               | Screw terminals SK |
| Family construction form | terminal           |
| Gender                   | female             |
| Color contact carrier    | green              |
| No. of poles             | 1                  |
| PIN 1                    | A 1                |
| Connection               | Screw terminals SK |
| Family construction form | terminal           |
| Gender                   | female             |
| Color contact carrier    | green              |
| No. of poles             | 1                  |
| PIN 1                    | A 2                |