



Article discontinued since March/2018

Product discontinued

Compact design
with plug relays
8 plugged relays; each 1 NO/NC contact
24 V DC
Diode + LED

Link to Product

Illustration

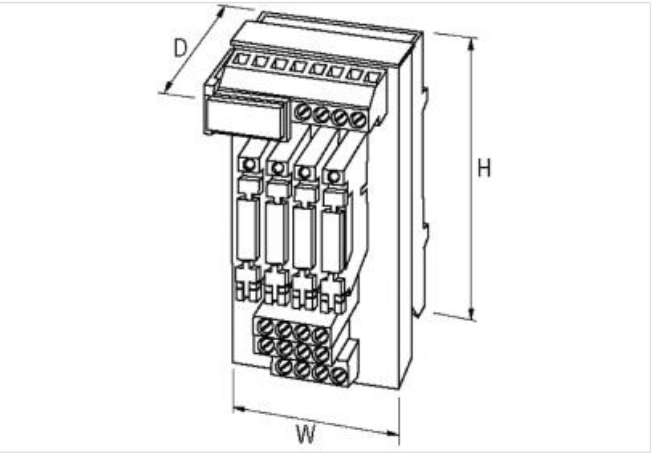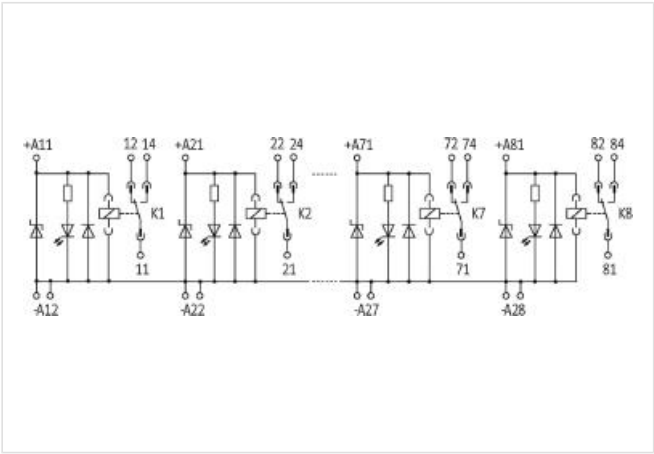

Product may differ from Image



Commercial data	
ECLASS-6.0	27371001
ECLASS-7.0	27371001
ECLASS-8.0	27371001
ECLASS-9.0	27371001
ETIM-5.0	EC001437

customs tariff number	85437090
GTIN	4048879411332
Packaging unit	1

Electrical data | Supply

Current consumption	10 mA
---------------------	-------

Electrical data | Output

Utilization category AC-12 (EN IEC 60947-5-1)	6 A @ 24, 6 A @ 110 V, 6 A @ 230 V
Utilization category AC-15 (EN IEC 60947-5-1)	3 A @ 24 V, 3 A @ 110 V, 3 A @ 230 V
Utilization category DC-13 (EN IEC 60947-5-1)	1 A @ 24 V, 0,2 A @ 110 V, 0,1 A @ 230 V
Switching voltage AC max.	250 V
Switching voltage DC max.	250 V
Switching current max.	6 A

Installation

Connection cross section max.	4 mm ²
-------------------------------	-------------------

Installation | Connection

Connection	Screw terminals SK
Connection information	mit einzeln ausgeführten -A2-Anschlüssen

Device protection | Electrical

Rated surge voltage	4 kV
---------------------	------

Mechanical data | Mounting data

Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	86 mm
Width	67,5 mm
Depth	75 mm