

**UFL 40 L PLUG FOR SIGNAL TRANSFER**

24 VDC / 1 A - male with LED




Ribbon cable connector + LED

40-pole


Via the combined fixing mechanism, connectors with or without strain relief can be connected.  
for plugs with or without strain relief (DIN 41651); for plugs with strain relief, it may be necessary to remove the bottom hook

[Link to Product](#)

Illustration

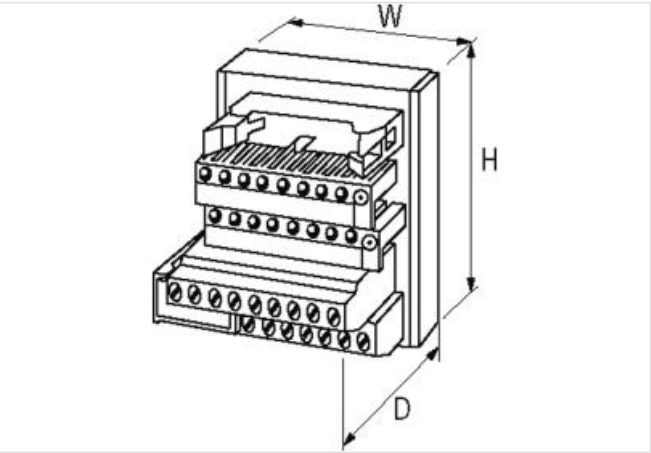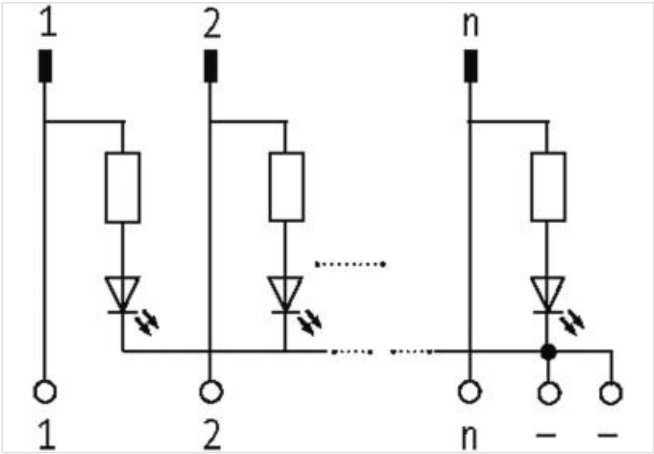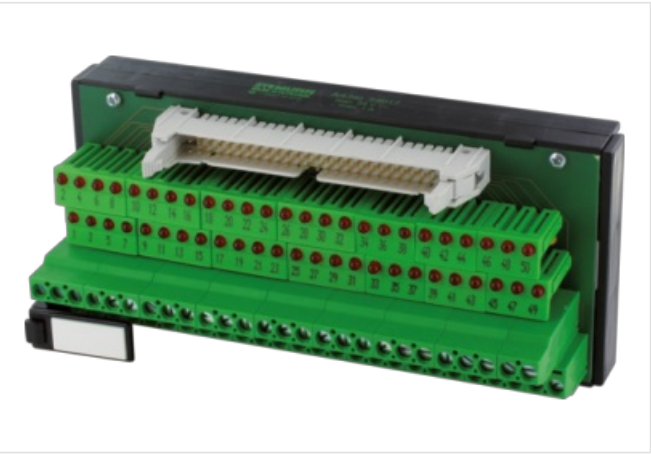

Product may differ from Image

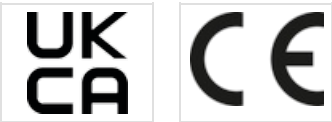

Commercial data	
ECLASS-6.0	27141120
ECLASS-6.1	27141120
ECLASS-7.0	27141120
ECLASS-8.0	27141120
ECLASS-9.0	27141120

ECLASS-10.1	27141120
ECLASS-11.1	27141120
ECLASS-12.0	27141120
ETIM-5.0	EC001283
customs tariff number	85366990
GTIN	4048879026574
Packaging unit	1
<b>Electrical data   Supply</b>	
Operating voltage AC	24 V
Operating current max.	1 A
<b>Diagnostics</b>	
Status indication LED	red
<b>Device protection   Electrical</b>	
Overvoltage category (EN 60664-1)	II
<b>Mechanical data   Mounting data</b>	
Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	63 mm
Width	120 mm
Depth	48 mm
<b>Environmental characteristics   Climatic</b>	
Operating temperature min.	-20 °C
Operating temperature max.	70 °C