




MA SI67 INSTALLATION TECHNOLOGY

Converter 2x profile cable to M12 female

MA SI67 converter  
2x profile cable to M12 (female)  
Connection cables are in the online shop under "Connection Technology".

Link to Product

Illustration

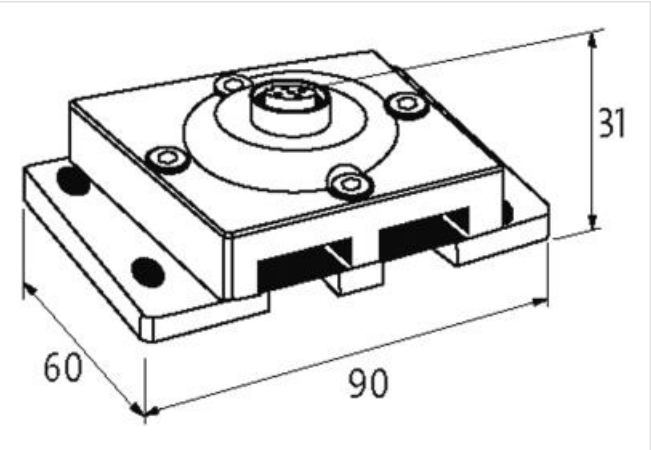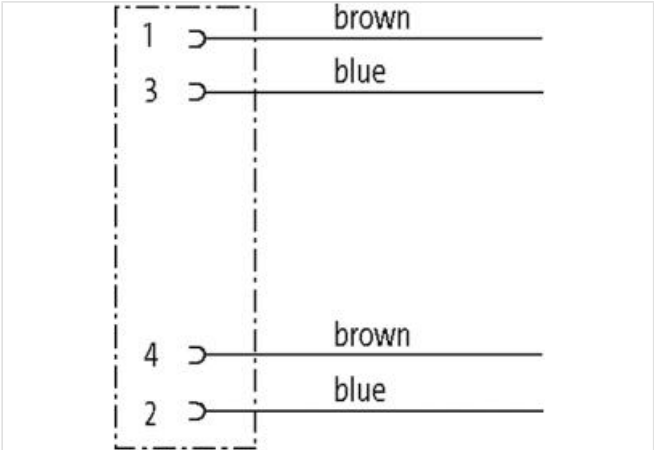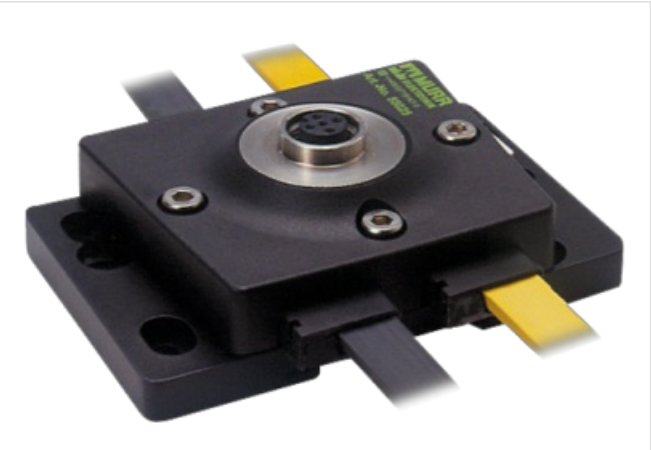

Product may differ from Image



| Commercial data |          |
|-----------------|----------|
| ECLASS-6.0      | 27400209 |
| ECLASS-6.1      | 27279219 |
| ECLASS-7.0      | 27279219 |
| ECLASS-8.0      | 27279219 |
| ECLASS-9.0      | 27440108 |
| ECLASS-10.1     | 27440111 |

|                       |               |
|-----------------------|---------------|
| ECLASS-11.1           | 27440111      |
| ECLASS-12.0           | 27440111      |
| ETIM-5.0              | EC001583      |
| customs tariff number | 85369010      |
| GTIN                  | 4048879052146 |
| Packaging unit        | 1             |

**Electrical data | Supply**

|                           |      |
|---------------------------|------|
| Operating voltage DC max. | 36 V |
| Total current max.        | 4 A  |

**Device protection | Electrical**

|                                     |       |
|-------------------------------------|-------|
| Degree of protection (EN IEC 60529) | IP67  |
| Insulation strength ASI/Power       | 200 V |

**Mechanical data | Mounting data**

|                            |                           |
|----------------------------|---------------------------|
| Mounting method            | screwed, geschnappt       |
| Suitable for mounting type | mounting rail, (EN 60715) |
| Height                     | 90 mm                     |
| Width                      | 74 mm                     |
| Depth                      | 30,5 mm                   |

**Environmental characteristics | Climatic**

|                            |        |
|----------------------------|--------|
| Operating temperature min. | -20 °C |
| Operating temperature max. | 60 °C  |
| Storage temperature min.   | -40 °C |
| Storage temperature max.   | 80 °C  |

**Conformity**

|                  |            |
|------------------|------------|
| Product standard | EN 60664-1 |
|------------------|------------|

**Connection type 1**

|                          |         |
|--------------------------|---------|
| Connection type 1        | Bus Out |
| Family construction form | M12     |
| Gender                   | female  |
| Color contact carrier    | black   |
| Coding                   | A       |
| No. of poles             | 5       |
| PIN 1                    | AS-i +  |
| PIN 2                    | 0 V     |
| PIN 3                    | AS-i -  |
| PIN 4                    | 24 V DC |
| PIN 5                    | n.c.    |