

CUBE67 ACCESSORIES

System interface connector


M12  
Female straight  
Internal system connection  
with mounting socket  
Flange, hole spacing 30 mm, bore 3.3 mm

Link to Product

Illustration



Product may differ from Image

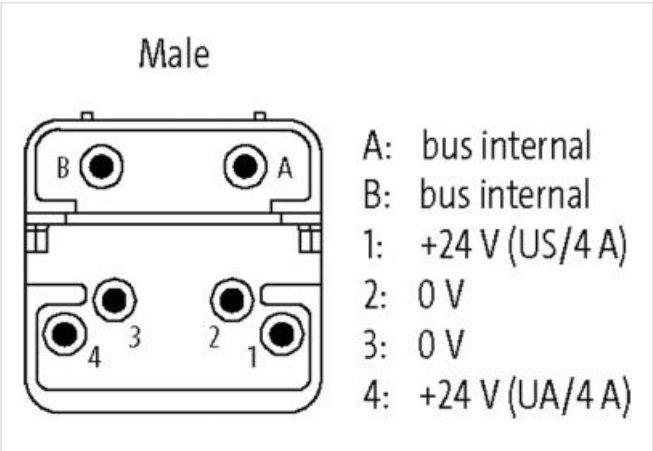

Commercial data

ECLASS-6.0	27242692
ECLASS-6.1	27242692
ECLASS-7.0	27242692
ECLASS-8.0	27242692
ECLASS-9.0	27242692
ECLASS-10.1	27242692
ECLASS-11.1	27242692
ECLASS-12.0	27242692
ETIM-5.0	EC001583
customs tariff number	85366990
GTIN	4048879047890
Packaging unit	1

Electrical data | Supply

Operating voltage DC	24 V
Operating current max.	4 A

Installation | Connection

Connection information	Han-Brid®, 6-polig
Family construction form	M12
Gender	female
Mating cycles min.	500

Installation | Pin assignment

No. of poles	6
--------------	---

Device protection | Electrical

Degree of protection (EN IEC 60529) IP65

**Mechanical data | Mounting data**

Height	80,5 mm
Width	40 mm
Depth	40 mm

**Environmental characteristics | Climatic**

Operating temperature min.	-40 °C
Operating temperature max.	85 °C