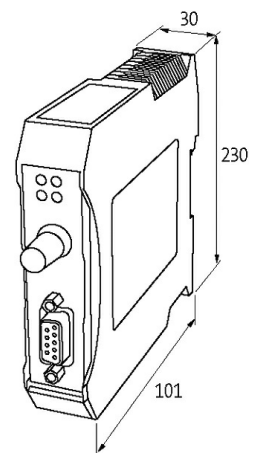


**MIRO BT DP 1,5 S-4 - phasing out of this product**

Bluetooth Slave Profibus-DP 1,5 Mbit/s max. 4 participants

PROFIBUS  
Radio Slave Module  
1.5 Mbit/s

[Link to Product](#)**Illustration**

Product may differ from Image

**Technical Data**

Operating voltage	9...33 V DC
Frequency	2.4 GHz Bluetooth
Current consumption	200 mA (24 V DC)
Transfer rate	1.5 Mbit/s

**General data**

Standards	approved in: BE, DK, DE, EE, FI, FR (restricted), GB, IE, IS, IT, CA, LV, LT, LU, MT, NL, NO (without Spitzbergen), AT, PL, PT, SE, CH, SK, SI, EL, ES, CZ, HU, US, CY
Housing	Black plastic
Protection	IP54
Dimensions HxWxD	230x101x30 mm
Connection	Screw terminals: max. 2.5 mm <sup>2</sup> (AWG 14)
Mounting method	DIN-rail mountable TH35 (EN 60715)

The information in this brochure has been compiled with the utmost care.  
Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 05/21

Temperature range -20...+60 °C (storage temperature -40...+75 °C)

**Connections**

Fieldbus SUB-D, 9-pole

**Commercial data**

country of origin	DE
customs tariff number	85176200
EAN	4048879364980
Packaging unit	1