

Memory Card 16GB


UHS class 1, speed class 10
 µSD card
 16 GB, EXFAT formatted
 Industrial standard

[Link to Product](#)

Illustration



Product may differ from Image

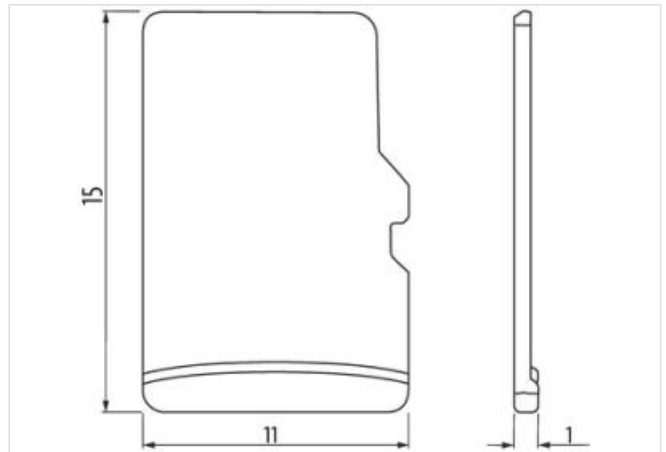

Electrical data | Supply

Power consumption max. 0,66 W

Electrical data | Input

Input voltage DC min. 2,7 V

Input voltage DC max. 3,6 V

Industrial communication | Memory interface

Formatting EXFAT

Speed class 10

Reading speed max. (data) 90 MBit/s

Writing speed max. (data) 80 MBit/s

Memory card (type) Micro SD

Memory card max. (capacity) 16 GB

UHS class I

Transmission mode SD 1.1, SD 2.0, SD 3.0, SPI

Mechanical data | Mounting data

Height 15 mm

Width 11 mm

Depth 1 mm

Environmental characteristics | Climatic

Operating temperature min. -25 °C

Operating temperature max. 85 °C

Storage temperature min. -25 °C

Storage temperature max. 85 °C

Commercial data

customs tariff number 85235110

Packaging unit 1

