



ASSEMBLY MODULE MP 6

Mounting rail / screw-type terminal

6 pairs of solder pins  
screw terminals connected to solder pin pairs

Link to Product

Illustration

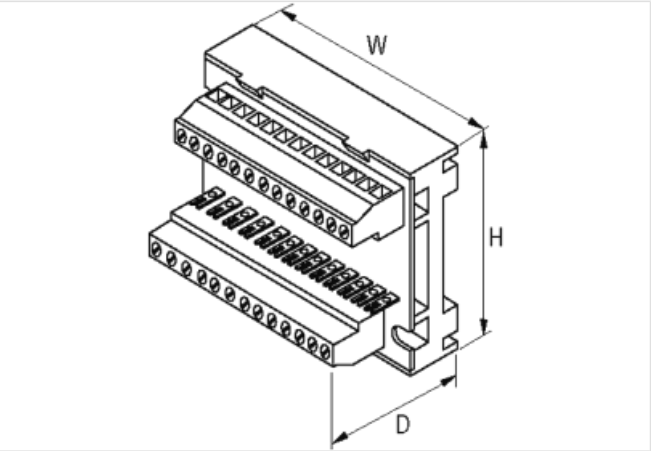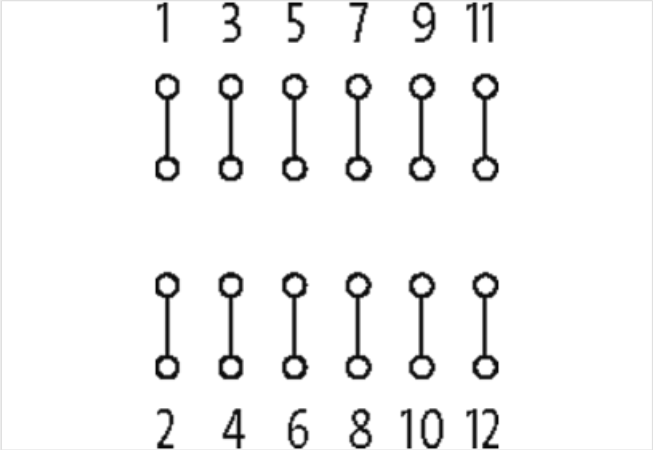

Product may differ from Image



Commercial data	
ECLASS-6.0	27260710
ECLASS-6.1	27141149
ECLASS-7.0	27141149
ECLASS-8.0	27141149
ECLASS-9.0	27141149
ECLASS-10.1	27141149
ECLASS-11.1	27141149
ECLASS-12.0	27141149

ETIM-5.0	EC000683
customs tariff number	85369010
GTIN	4048879042277
Packaging unit	1
<b>Electrical data   Supply</b>	
Operating voltage AC	50 V
Operating voltage DC	50 V
Operating current max.	5 A
<b>Installation</b>	
Connection cross section max.	4 mm <sup>2</sup>
<b>Installation   Connection</b>	
Connection	Screw terminals SK
Connection information	Lötstützpunktpaare (Raster 5 mm)
<b>Device protection   Media</b>	
Flame resistance	flame retardant
<b>Mechanical data   Material data</b>	
Housing properties	open design
Material housing	Plastic
<b>Mechanical data   Mounting data</b>	
Distance of solder pins	24 mm
Mounting method	screwed, geschnappt
Suitable for mounting type	Mounting rail TH35, G32, (EN 60715)
Height	63 mm
Width	45 mm
Depth	36 mm
<b>Environmental characteristics   Climatic</b>	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C