



MET 1-Phase control and isolating transformer

P: 2500VA IN: 230-400VAC +/- 15VAC OUT: 115VAC


The MET series comprises single-phase control transformers/isolating transformers of the protection class I and protection degree IP00 with double insulation between the primary and secondary windings for general use in industrial applications.

Link to Product

Illustration

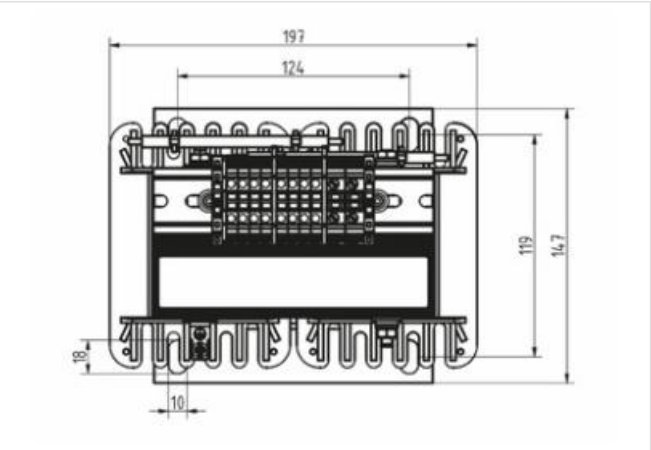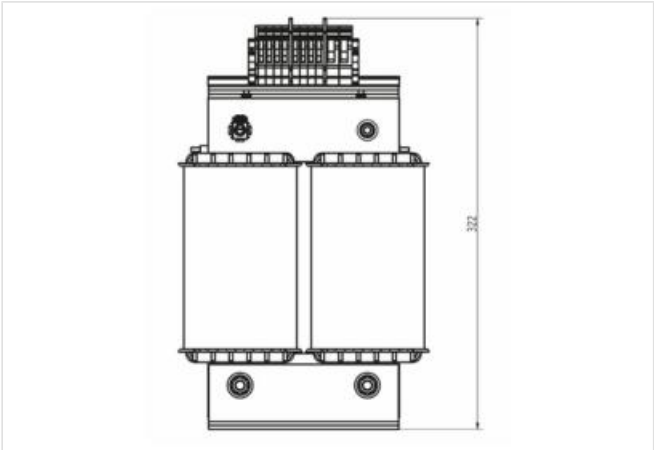

Product may differ from Image

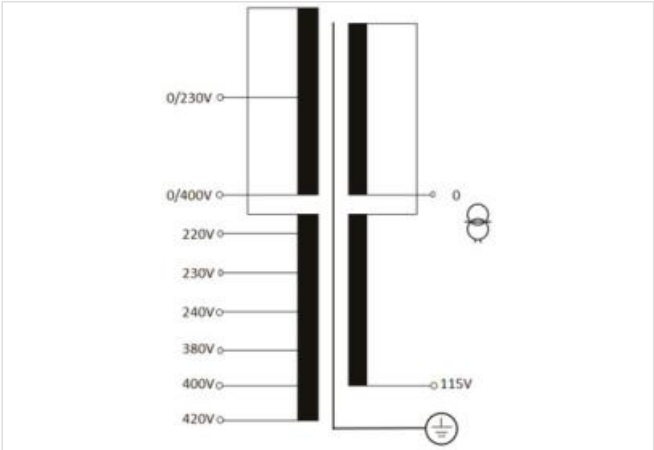

Electrical data | Supply

Power frequency 50/60 Hz

Electrical data | Input

Input voltage 1 AC	230 V
Input voltage 2 AC	400 V
Input current at input voltage 1 AC	11,2 A
Input current at input voltage 2 AC	6,4 A

Inrush current at input voltage 1	212 A
Inrush current at input voltage 2	122 A
Short-circuit current at input voltage 1	411 A
Short-circuit current at input voltage 2	236 A

Electrical data | Output

Output voltage AC	115 V
-------------------	-------

Mechanical data | Mounting data

Mounting method	screwed
Suitable for mounting type	4 hole screw mounting
Mounting dimension a	119 mm
Mounting dimension b	124 mm
Mounting dimension c	10 mm
Height	147 mm
Width	197 mm
Depth	322 mm
Diameter bore	10 mm
Length bore	18 mm

Environmental characteristics | Climatic

Ambient temperature min.	-20 °C
Ambient temperature max.	50 °C
Storage temperature min.	-30 °C
Storage temperature max.	80 °C

Conformity

Product standard	EN 61558-1, EN 61558-2-4, EN 62041
EMC	2014/30/EU

Commercial data

customs tariff number	85043200
GTIN	4065909080795
Packaging unit	1