




MOTOR SUPPRESSION SHIELDING PLUGGABLE

5M PUR 5,5KW-3X575

3× 575 V AC
VDR/star
5.0 m
PUR cable black, 4× 1.5 mm², numbered wires, DESINA conform

[Link to Product](#)

Illustration

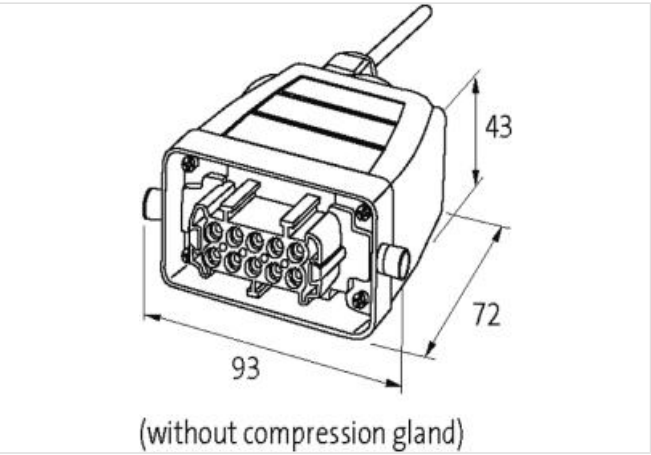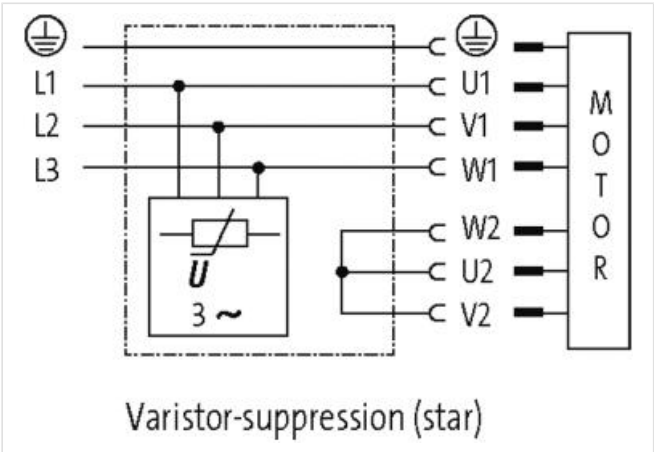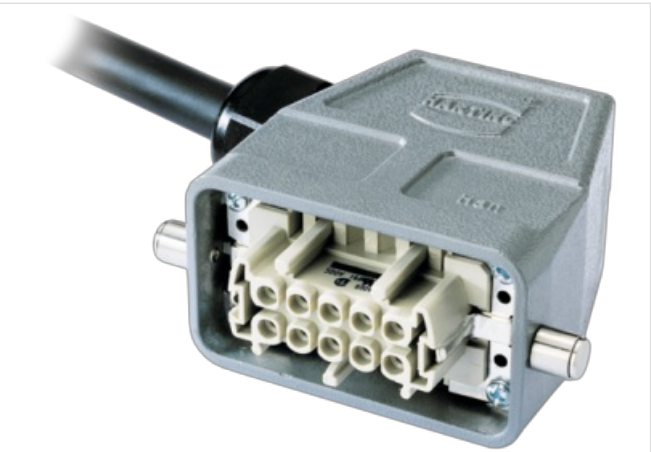

Product may differ from Image



Commercial data	
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013

ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC000197
customs tariff number	85363010
GTIN	4048879015134
Packaging unit	1

Electrical data | Supply

Power frequency	10 ... 400 Hz
-----------------	---------------

Electrical data | Input

Input voltage AC min.	400 V
Input voltage AC max.	575 V

Installation | Connection

Gender	female
--------	--------

Installation | Pin assignment

No. of poles	10 + PE
--------------	---------

Mechanical data | Material data

Coating housing	powder-coated
Material housing	Aluminum die casting

Mechanical data | Mounting data

Height	43 mm
Width	93 mm
Depth	72 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C