

M12-DISTRIBUTOR BOX 4-WAY, 5-POLE WITHOUT LED

MVC4-UQQ5.0-XA 5m PUR-CNOMO-cable 8x0,34/3x1


4-way, 5-pole  
PUR/PVC (CNOMO)  
5.0 m  
without LED

Link to Product

Illustration



Product may differ from Image

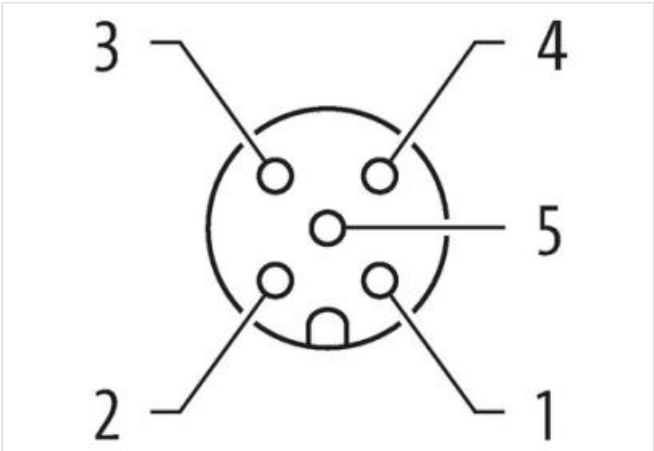

Commercial data

ECLASS-6.0	27279219
ECLASS-7.0	27279219
ECLASS-8.0	27279219
ECLASS-9.0	27440108
ETIM-5.0	EC002585
customs tariff number	85444290
GTIN	4048879000178
Packaging unit	1

Electrical data | Supply

Operating voltage DC	24 V
Current operating per contact max.	4 A
Total current max.	10 A

Industrial communication

Number of signals per port	2
----------------------------	---

Installation | Connection

Mounting set	M12 x 1
--------------	---------

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP67
Additional condition protection degree	inserted, screwed

Mechanical data | Mounting data

Mounting method	Schraubgewinde
Height	117 mm
Width	54 mm

Depth 33 mm

**Environmental characteristics | Climatic**

Operating temperature min.	-20 °C
Operating temperature max.	80 °C

**Connection type 2**

Family construction form	free cable end
No. of poles	11
Family construction form	M12
Gender	female
Color contact carrier	black
Coding	A
No. of poles	5
PIN 1	+
PIN 3	-
PIN 5	PE