
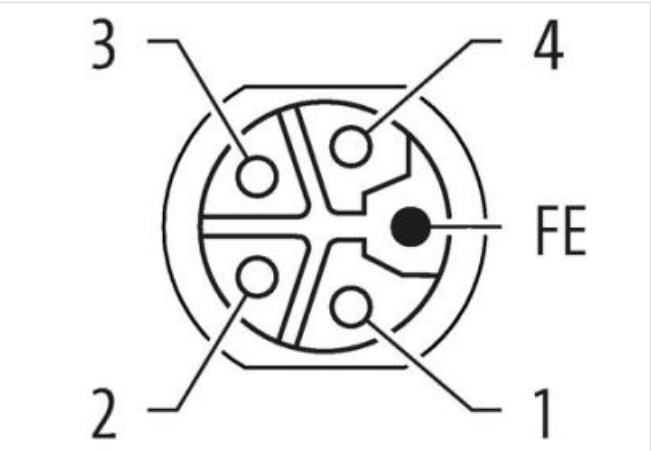


Power Distributor 4x L-cod.

Passive power distributor in zinc die-cast housing
B24 with locking on both sides
Industrial connector 24-pin + PE to 4x M12 L 5P female

Link to Product

Illustration

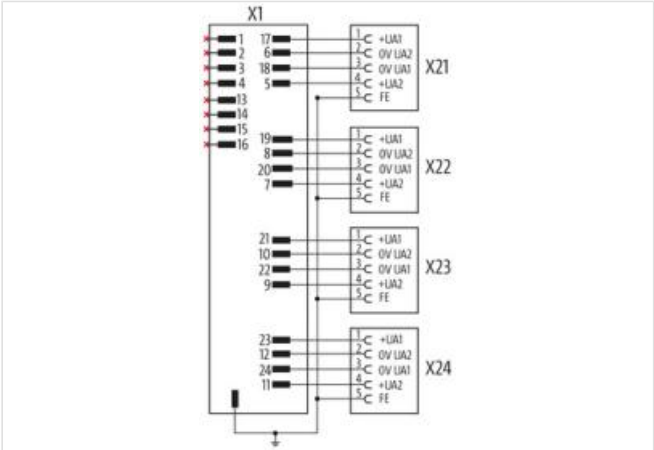

Product may differ from Image

Electrical data Supply	
Operating voltage AC	48 V
Operating voltage DC	48 V
Current operating per contact max.	16 A
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP65
Additional condition protection degree	inserted, locked
Mechanical data Material data	
Coating housing	powder-coated
Material housing	Aluminum die casting
Mechanical data Mounting data	
Height	94 mm
Width	61 mm

Depth	149 mm
Looking techniques	2-hand fixing (2 clamps)
Environmental characteristics Climatic	
Operating temperature min.	-25 °C
Operating temperature max.	70 °C
Storage temperature min.	-25 °C
Storage temperature max.	85 °C
Commercial data	
customs tariff number	85366990
GTIN	4048879867504
Packaging unit	1