


MET SINGLE-PHASE SAFETY TRANSFORMER

P:100VA IN:110VAC OUT:24VAC with fuse-clamp

Single-phase - Control and Isolation Transformers
100 VA
Isolation class T 60/B
with fuse

[Link to Product](#)

Illustration

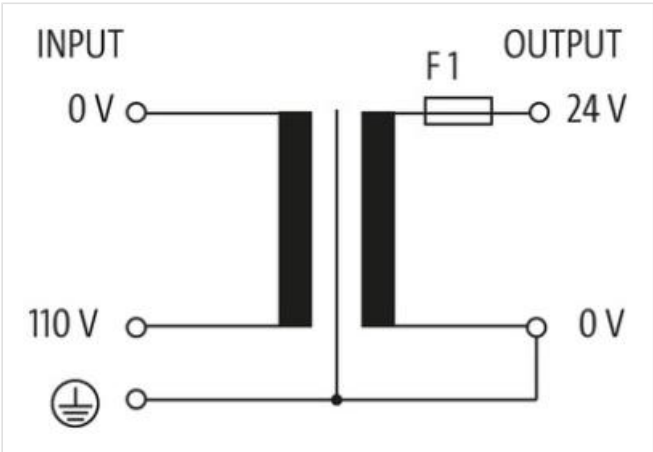

Product may differ from Image

Commercial data	
ECLASS-6.0	27031202
ECLASS-7.0	27031202
ECLASS-8.0	27031202
ECLASS-9.0	27031202
ETIM-5.0	EC002485
customs tariff number	85043180
GTIN	4048879073776
Packaging unit	1

Electrical data Supply	
Power frequency	50 ... 60 Hz

Electrical data Input	
Input voltage 1 AC	110 V
Input voltage AC	110 V
Current input AC	1,07 A
Max. inrush current	9 A
Short-circuit current	12 A
Electrical data Output	
Output voltage AC	24 V
Output voltage adjustable	no
Power rating AC max.	100 VA
Device protection Electrical	
Insulation test voltage input - output	3,5 kV
Mechanical data Mounting data	
Suitable for mounting type	Schlüssellochabhängung
Mounting dimension a	47 mm
Mounting dimension b	64 mm
Mounting dimension c	4,8 mm
Height	82 mm
Width	6 mm
Depth	105 mm
Diameter bore	4,8 mm
Length bore	8 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C
Conformity	
Product standard	EN 61558-2-4, EN 61558-2-6, EN 62041 category 0