



MET SINGLE-PHASE CONTROL AND ISOLATION TRANSFORMER

P:2000VA IN:400VAC±5% OUT:230VAC

Single-phase - Control and Isolation Transformers
2000 VA
Isolation class T 40/B
Varnished board

[Link to Product](#)

Illustration

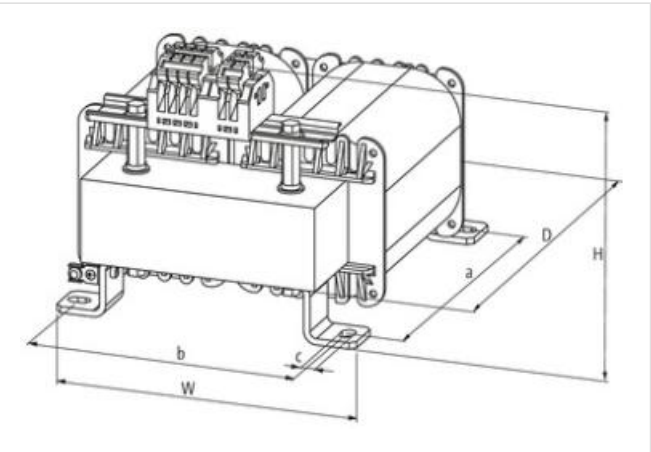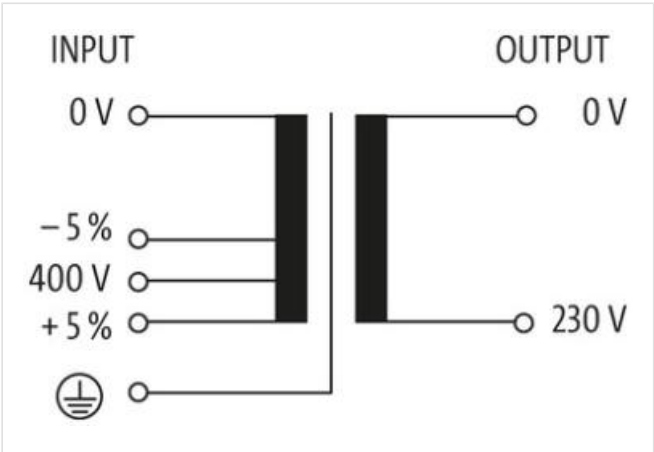

Product may differ from Image

Commercial data

ECLASS-6.0	27031202
ECLASS-7.0	27031202
ECLASS-8.0	27031202
ECLASS-9.0	27031202
ETIM-5.0	EC002485
customs tariff number	85043200
GTIN	4048879301527
Packaging unit	1

Electrical data | Supply

Power frequency 50 ... 60 Hz

Electrical data | Input

Input voltage AC	400 V
Input voltage AC min.	380 V
Input voltage AC max.	420 V
Current input AC	5,1 A
Max. inrush current	76 A
Short-circuit current	182 A

Electrical data | Output

Output voltage AC	230 V
Output voltage adjustable	no
Power rating AC max.	2000 VA

Device protection | Electrical

Insulation test voltage input - output	4 kV
--	------

Mechanical data | Mounting data

Suitable for mounting type	Long-hole mounting
Mounting dimension a	200 mm
Mounting dimension b	174 mm
Mounting dimension c	9 mm
Height	170 mm
Width	197 mm
Depth	250 mm
Diameter bore	9 mm
Length bore	14 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	40 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C

Conformity

Product standard	EN 61558-1, EN 61558-2-4, EN 62041 category 0
------------------	---