


VALVE PLUG SUPPRESSOR FORM B - 10MM

Diode and LED, 24VDC/50VA/W

[Link to Product](#)

Illustration

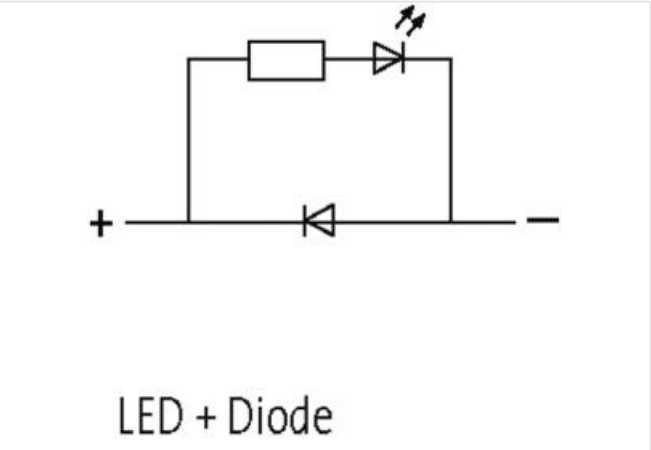

Product may differ from Image

Commercial data	
ECLASS-6.0	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ETIM-5.0	EC000197
customs tariff number	85363010
GTIN	4048879011501
Packaging unit	1
Electrical data	
Capacity CX	200 ms
Holding power max.	50 W
Electrical data Supply	
Cut-off peak voltage max.	1 V
Diagnostics	
Status indication LED	yellow
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Coating contact	silver-plated
Color housing	black
Material housing	PA
Material contact	Bronze
Mechanical data Mounting data	
Height	15 mm
Width	63 mm
Depth	21,5 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C

Operating temperature max.	60 °C
Housing temperature max. (EN 61347-2-13)	130 °C