


MIRO IMPULSE EXTENSION MODULES

IN: 24 VDC - OUT: 24 VDC / 0.1 A

Transistor output  
Impulse expansion: 0.1...10 s  
Spring clamp terminals

[Link to Product](#)

Illustration

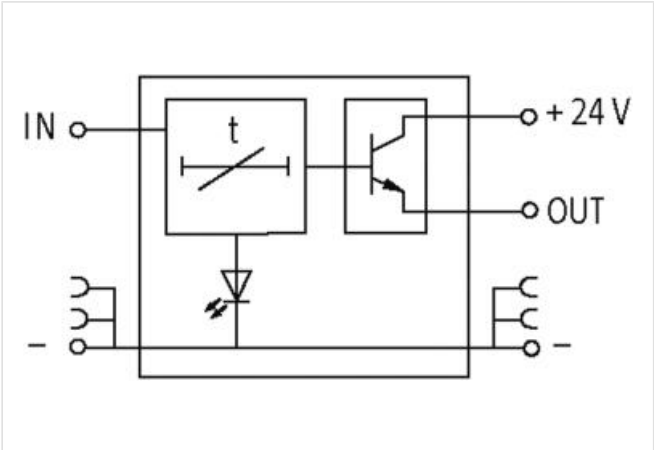

Product may differ from Image



| Commercial data |          |
|-----------------|----------|
| ECLASS-6.0      | 27371790 |
| ECLASS-6.1      | 27371790 |
| ECLASS-7.0      | 27371790 |
| ECLASS-8.0      | 27371605 |
| ECLASS-9.0      | 27371605 |
| ECLASS-10.1     | 27371605 |

|                       |               |
|-----------------------|---------------|
| ECLASS-11.1           | 27371605      |
| ECLASS-12.0           | 27371605      |
| ETIM-5.0              | EC001439      |
| customs tariff number | 85437090      |
| GTIN                  | 4048879021913 |
| Packaging unit        | 1             |

**Electrical data | Input**

|                         |        |
|-------------------------|--------|
| Input voltage DC min.   | 19 V   |
| Input voltage DC max.   | 29 V   |
| Pulse length min.       | 0,5 ms |
| Control voltage DC min. | 16 V   |
| Control voltage DC max. | 32 V   |

**Electrical data | Output**

|                        |        |
|------------------------|--------|
| Output voltage DC      | 24 V   |
| Pulse time min.        | 0,1 s  |
| Pulse time max.        | 10 s   |
| Switching current max. | 100 mA |

**Mechanical data | Mounting data**

|                            |                           |
|----------------------------|---------------------------|
| Mounting method            | geschnappt                |
| Suitable for mounting type | mounting rail, (EN 60715) |
| Height                     | 91 mm                     |
| Width                      | 6,2 mm                    |
| Depth                      | 70 mm                     |

**Environmental characteristics | Climatic**

|                            |       |
|----------------------------|-------|
| Operating temperature min. | 0 °C  |
| Operating temperature max. | 60 °C |

**Connection type 4**

|                          |                           |
|--------------------------|---------------------------|
| Connection               | Spring clamp terminals FK |
| Family construction form | terminal                  |
| Gender                   | female                    |
| Color contact carrier    | black                     |
| No. of poles             | 1                         |
| PIN 1                    | +                         |
| Connection               | Spring clamp terminals FK |
| Family construction form | terminal                  |
| Gender                   | female                    |
| Color contact carrier    | black                     |
| No. of poles             | 1                         |
| PIN 1                    | -                         |
| Connection               | Spring clamp terminals FK |
| Family construction form | terminal                  |
| Gender                   | female                    |
| Color contact carrier    | black                     |
| No. of poles             | 1                         |
| PIN 1                    | Out                       |
| Connection               | Spring clamp terminals FK |
| Family construction form | terminal                  |
| Gender                   | female                    |
| Color contact carrier    | black                     |
| No. of poles             | 1                         |
| PIN 1                    | In                        |