

SUPPRESSOR FOR SIEMENS CONTACTOR S00 MOTOR

RC, star, 3x575 VAC, 7.5 kV



3× 575 V AC

RC

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

Link to Product

Illustration

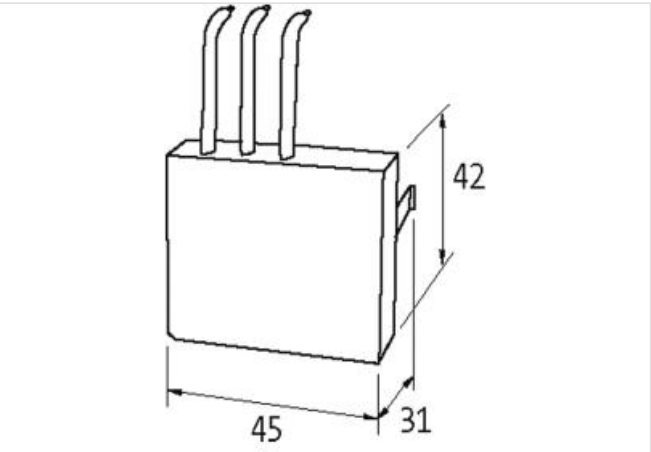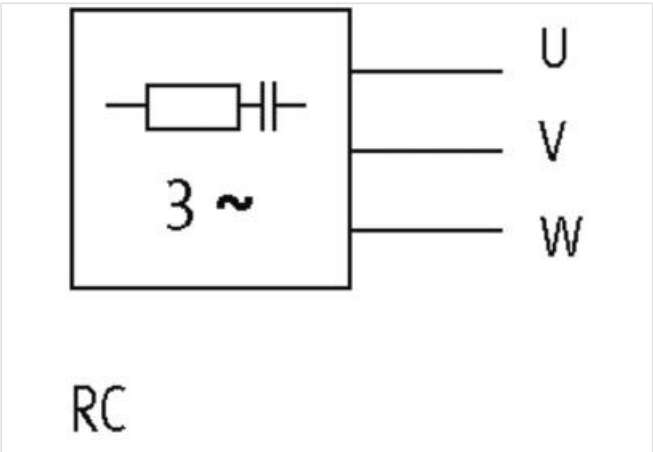

Product may differ from Image

| Commercial data       |               |
|-----------------------|---------------|
| ECLASS-6.0            | 27371013      |
| ECLASS-6.1            | 27371013      |
| ECLASS-7.0            | 27371013      |
| ECLASS-8.0            | 27371013      |
| ECLASS-9.0            | 27371013      |
| ECLASS-10.1           | 27371013      |
| ECLASS-11.1           | 27371013      |
| ECLASS-12.0           | 27371013      |
| ETIM-5.0              | EC002498      |
| customs tariff number | 85363010      |
| GTIN                  | 4048879413176 |

|                |    |
|----------------|----|
| Packaging unit | 10 |
|----------------|----|

**Electrical data | Supply**

|                 |              |
|-----------------|--------------|
| Power frequency | 50 ... 60 Hz |
|-----------------|--------------|

**Electrical data | Input**

|                  |       |
|------------------|-------|
| Input voltage AC | 575 V |
|------------------|-------|

**Installation | Connection**

|                        |                  |
|------------------------|------------------|
| Connection information | Connection wires |
|------------------------|------------------|

**Device protection | Media**

|                  |                 |
|------------------|-----------------|
| Flame resistance | flame retardant |
|------------------|-----------------|

**Mechanical data | Material data**

|                                     |     |
|-------------------------------------|-----|
| Combustibility class housing (UL94) | V-0 |
|-------------------------------------|-----|

|                  |         |
|------------------|---------|
| Material housing | Plastic |
|------------------|---------|

|                           |                   |
|---------------------------|-------------------|
| Material potting compound | 2-component epoxy |
|---------------------------|-------------------|

**Mechanical data | Mounting data**

|                 |            |
|-----------------|------------|
| Mounting method | geschnappt |
|-----------------|------------|

|                            |                                                      |
|----------------------------|------------------------------------------------------|
| Suitable for mounting type | Siemens Schütz Sirius 3 RT 201 mit Federzuganschluss |
|----------------------------|------------------------------------------------------|

|        |       |
|--------|-------|
| Height | 42 mm |
|--------|-------|

|       |       |
|-------|-------|
| Width | 45 mm |
|-------|-------|

|       |       |
|-------|-------|
| Depth | 31 mm |
|-------|-------|

**Environmental characteristics | Climatic**

|                            |        |
|----------------------------|--------|
| Operating temperature min. | -20 °C |
|----------------------------|--------|

|                            |       |
|----------------------------|-------|
| Operating temperature max. | 60 °C |
|----------------------------|-------|