



**SIEMENS CONTACTOR SUPPRESSOR**

Diode and LED, 24VDC

24 V AC/DC  
48 V AC/DC  
Diode + LED  
For other configurations and voltages, please inquire.

[Link to Product](#)

Illustration

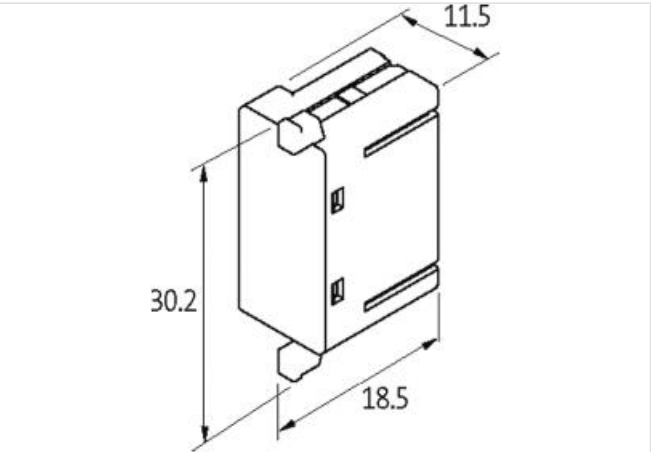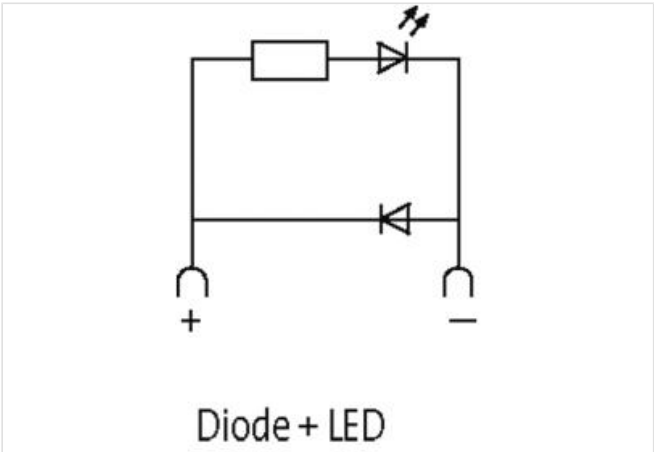

Product may differ from Image



| Commercial data |          |
|-----------------|----------|
| ECLASS-6.0      | 27371013 |
| ECLASS-6.1      | 27371013 |
| ECLASS-7.0      | 27371013 |
| ECLASS-8.0      | 27371013 |
| ECLASS-9.0      | 27371013 |
| ECLASS-10.1     | 27371013 |

|                                                 |                     |
|-------------------------------------------------|---------------------|
| ECLASS-11.1                                     | 27371013            |
| ECLASS-12.0                                     | 27371013            |
| ETIM-5.0                                        | EC002498            |
| customs tariff number                           | 85363010            |
| GTIN                                            | 4048879010894       |
| Packaging unit                                  | 1                   |
| <b>Compatibility   Compatible with</b>          |                     |
| Appropriate contactors                          | 3 RT 20.25/26/27/28 |
| <b>Electrical data</b>                          |                     |
| Damping factor                                  | 1.5× UN             |
| <b>Electrical data   Input</b>                  |                     |
| Input voltage DC min.                           | 21 V                |
| Input voltage DC max.                           | 27 V                |
| <b>Installation   Connection</b>                |                     |
| Connection information                          | Plug contact        |
| <b>Device protection   Media</b>                |                     |
| Flame resistance                                | flame retardant     |
| <b>Mechanical data   Material data</b>          |                     |
| Combustibility class housing (UL94)             | V-0                 |
| Material housing                                | Plastic             |
| <b>Mechanical data   Mounting data</b>          |                     |
| Height                                          | 18,5 mm             |
| Width                                           | 30,2 mm             |
| Depth                                           | 11,5 mm             |
| <b>Environmental characteristics   Climatic</b> |                     |
| Operating temperature min.                      | -20 °C              |
| Operating temperature max.                      | 70 °C               |