

TELEMECANIQUE CONTACTOR SUPPRESSOR

Varistor, 230VAC/DC



230 V AC/DC

VDR

For other configurations and voltages, please inquire.

Link to Product

Illustration

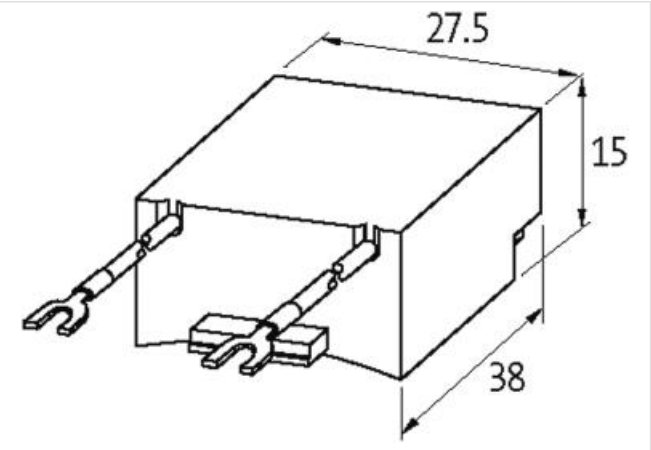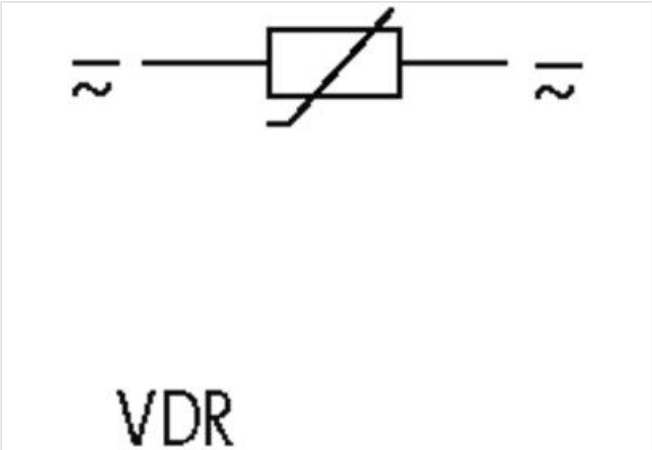

Product may differ from Image



| Commercial data |          |
|-----------------|----------|
| ECLASS-6.0      | 27371013 |
| ECLASS-6.1      | 27371013 |
| ECLASS-7.0      | 27371013 |
| ECLASS-8.0      | 27371013 |
| ECLASS-9.0      | 27371013 |
| ECLASS-10.1     | 27371013 |

|                                                 |                                                 |
|-------------------------------------------------|-------------------------------------------------|
| ECLASS-11.1                                     | 27371013                                        |
| ECLASS-12.0                                     | 27371013                                        |
| ETIM-5.0                                        | EC002498                                        |
| customs tariff number                           | 85363010                                        |
| GTIN                                            | 4048879010238                                   |
| Packaging unit                                  | 1                                               |
| <b>Compatibility   Compatible with</b>          |                                                 |
| Appropriate contactors                          | DT40, LC 1 D09...D38, LC 1 DT20, LC 2 D09...D38 |
| <b>Electrical data</b>                          |                                                 |
| Damping factor                                  | 1.5× UN                                         |
| <b>Electrical data   Input</b>                  |                                                 |
| Input voltage AC min.                           | 127 V                                           |
| Input voltage AC max.                           | 253 V                                           |
| Input voltage DC min.                           | 127 V                                           |
| Input voltage DC max.                           | 253 V                                           |
| <b>Installation   Connection</b>                |                                                 |
| Connection information                          | self-securing cable forks                       |
| <b>Device protection   Media</b>                |                                                 |
| Flame resistance                                | flame retardant                                 |
| <b>Mechanical data   Material data</b>          |                                                 |
| Combustibility class housing (UL94)             | V-0                                             |
| Material housing                                | Plastic                                         |
| <b>Mechanical data   Mounting data</b>          |                                                 |
| Height                                          | 15 mm                                           |
| Width                                           | 27,5 mm                                         |
| Depth                                           | 38 mm                                           |
| <b>Environmental characteristics   Climatic</b> |                                                 |
| Operating temperature min.                      | -20 °C                                          |
| Operating temperature max.                      | 70 °C                                           |