


MIRO 6.2 PLUGGABLE PLUG IN MODULE OUTPUT RELAY

IN: 6 VAC/DC - OUT: 250 VAC/DC / 6 A

[Link to Product](#)

Illustration

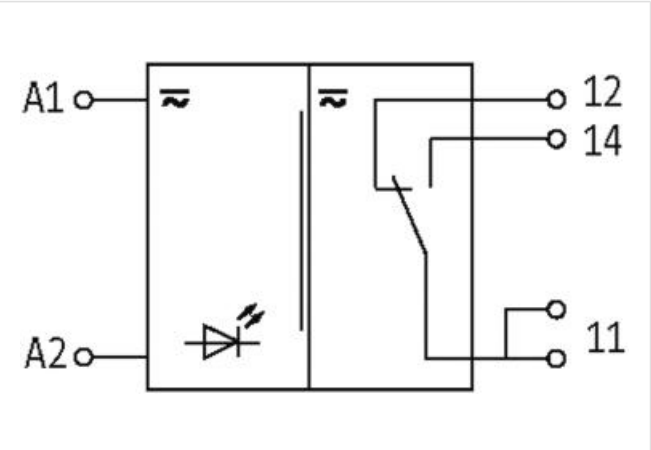

Product may differ from Image

Commercial data	
ECLASS-6.0	27371601
ECLASS-6.1	27371601
ECLASS-7.0	27371601
ECLASS-8.0	27371601
ECLASS-9.0	27371601
ECLASS-10.1	27371601
ECLASS-11.1	27371601
ECLASS-12.0	27371601
ETIM-5.0	EC001437
customs tariff number	85364900
GTIN	4048879021395
Packaging unit	1
Electrical data Input	
Input voltage AC	6 V
Input voltage DC	6 V
Electrical data Output	
Power rating AC max.	1500 VA
Power rating DC max.	120 W
Switching voltage AC max.	250 V
Switching voltage DC max.	30 V
Switching current DC	10 mA
Switching current max.	6 A
Device protection Electrical	
Rated insulation voltage	300 V
Mechanical data	
Drop-out time max.	4 ms
Response time max.	8 ms
Mechanical data Material data	
Material contact	Ag Sn O2

Mounting method	inserted
-----------------	----------

Operating temperature min. -40 °C

Operating temperature max.	60 °C
----------------------------	-------

Storage temperature min.	-40 °C
--------------------------	--------

Storage temperature max.	60 °C
--------------------------	-------