


MIRO 6.2 PLUGGABLE PLUG IN MODULE INPUT RELAY

IN: 24 VDC - OUT: 250 VAC/DC / 6 A

[Link to Product](#)

Illustration

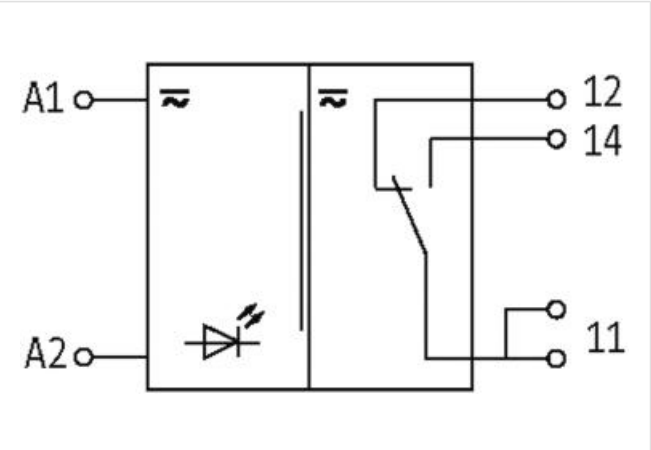

Product may differ from Image

Commercial data	
ECLASS-6.0	27371601
ECLASS-6.1	27371601
ECLASS-7.0	27371601
ECLASS-8.0	27371601
ECLASS-9.0	27371601
ECLASS-10.1	27371601
ECLASS-11.1	27371601
ECLASS-12.0	27371601
ETIM-5.0	EC001437
customs tariff number	85364900
GTIN	4048879021357
Packaging unit	1
Electrical data Input	
Input voltage AC	24 V
Input voltage DC	24 V
Electrical data Output	
Switching voltage AC max.	250 V
Switching voltage DC max.	30 V
Switching current DC	1 mA
Switching current max.	6 A
Device protection Electrical	
Rated insulation voltage	300 V
Mechanical data	
Drop-out time max.	6 ms
Response time max.	5 ms
Mechanical data Material data	
Material contact	Ag Sn O2
Mechanical data Mounting data	

Mounting method	inserted
Height	15 mm
Width	5 mm
Depth	28 mm
Environmental characteristics Climatic	
Operating temperature min.	-40 °C
Operating temperature max.	60 °C
Storage temperature min.	-40 °C
Storage temperature max.	60 °C