


MODLINK MSDD DBL COMBI INSERT FRANCE

1xRJ45 fem./fem. + RCD opening

- 1 × France (UTE-NF) white
- 1 × RJ45, 8-pole metal, CAT5e (female/female)
- 1 × FI cut-out

Link to Product

Illustration

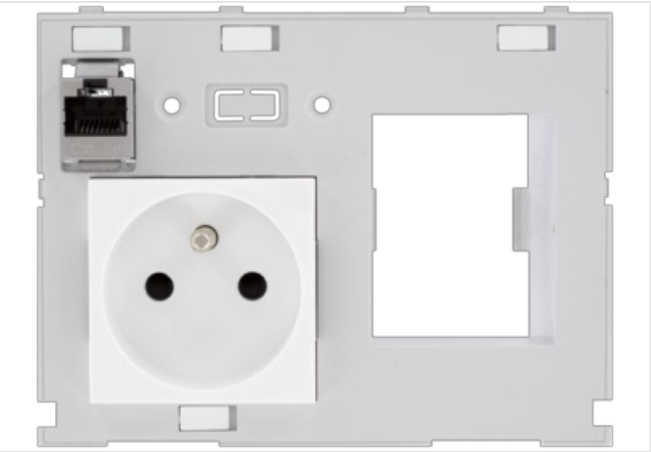

Product may differ from Image



Commercial data

ECLASS-6.0	27189217
ECLASS-6.1	27189217
ECLASS-7.0	27189217
ECLASS-8.0	27189217
ECLASS-9.0	27182806
ECLASS-10.1	27182806
ECLASS-11.1	27182806
ECLASS-12.0	27182806
ETIM-5.0	EC000020
customs tariff number	85366990
GTIN	4048879384513
Packaging unit	1

Mechanical data | Mounting data

Height	88 mm
Width	116 mm
Depth	70 mm

Environmental characteristics | Climatic

Storage temperature min.	5 °C
Storage temperature max.	40 °C

Shielding plate

Connection information	Threaded hole M4
------------------------	------------------

Tightening torque 0,9 Nm

France (UTE-NF)

Connection cross section max.	4 mm ²
AWG number max.	12
Operating voltage AC	250 V
Operating current	16 A
Connection	Screw terminals SK
No. of poles	2 + PE
Connections per pole	2
Protection contact present	yes

RJ45

Operating voltage AC max. (UL-listed)	30 V
Operating voltage DC max. (UL-listed)	42,4 V
Current operating max. (UL)	175 mA
Family construction form	RJ45
Family type Back side	RJ45
Cable category min.	Cat5e
Looking techniques	Snap-in connector