

SVS VALVE PLUG FORM B 10 MM FIELD-WIREABLE




0...230V M16x1.5

Form B (10 mm)  
max. 230 V AC/DC  
without components  
metric

Plastic housings with good resistance against chemicals and oils.  
The resistance to aggressive media should be individually tested for your application. Further details on request.

Link to Product

Illustration

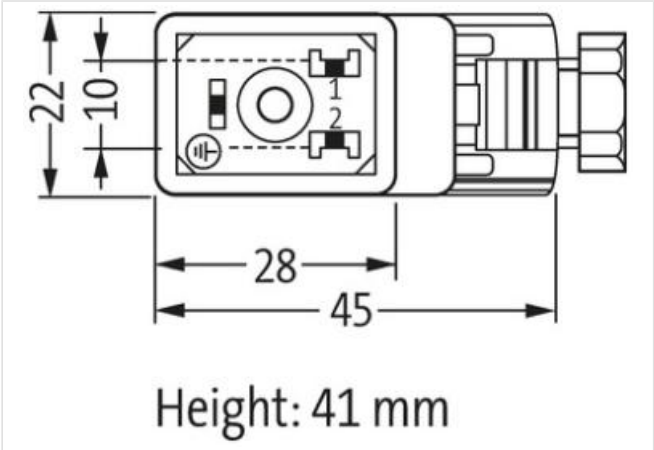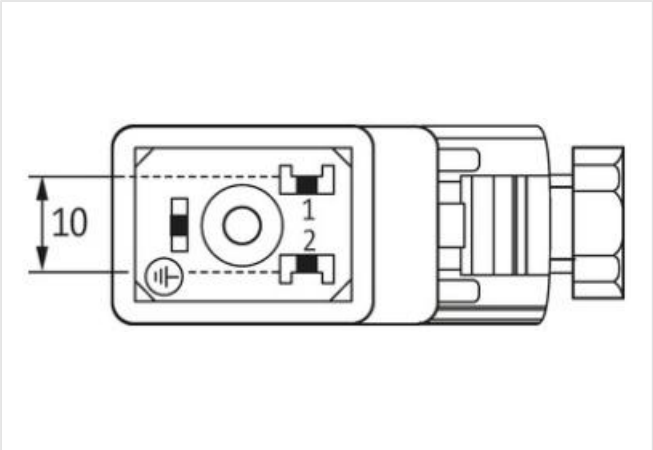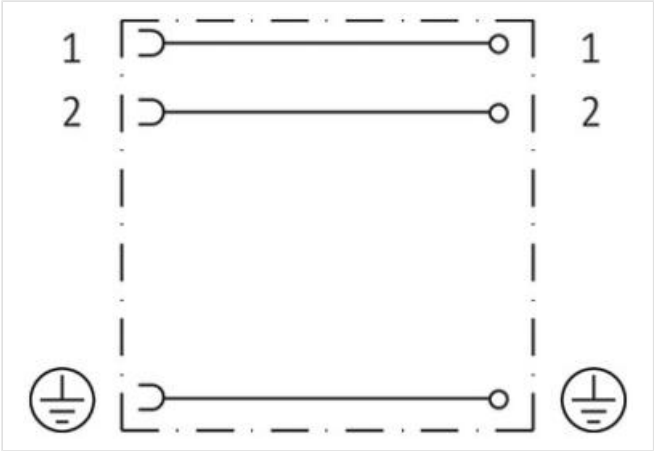

Product may differ from Image

Side 1	
Degree of protection (EN IEC 60529)	IP65
Commercial data	
ECLASS-6.0	27279221
ECLASS-7.0	27440104
ECLASS-8.0	27440104
ECLASS-9.0	27440102
ETIM-5.0	EC002062
customs tariff number	85366990

GTIN	4048879187220
------	---------------

Packaging unit	1
----------------	---

**Electrical data | Supply**

Operating voltage AC max.	230 V
---------------------------	-------

Operating voltage DC max.	230 V
---------------------------	-------

Current operating per contact max.	10 A
------------------------------------	------

**Installation**

Connection cross section max.	1,5 mm <sup>2</sup>
-------------------------------	---------------------

**Installation | Connection**

Tightening torque	0,4 Nm
-------------------	--------

Mounting set	M16 x 1.5
--------------	-----------

**Device protection | Electrical**

Additional condition protection degree	inserted, locked, with screw connection
--	---

**Mechanical data | Mounting data**

fastening screw	M3
-----------------	----

Clamping range min.	5 mm
---------------------	------

Clamping range max.	10 mm
---------------------	-------

**Environmental characteristics | Climatic**

Operating temperature min.	-20 °C
----------------------------	--------

Operating temperature max.	60 °C
----------------------------	-------