

SVS VALVE PLUG FORM B 10 MM FIELD-WIREABLE



0...230V PG9

Form B (10 mm)  
max. 230 V AC/DC  
without components  
PG9

Plastic housings with good resistance against chemicals and oils.  
The resistance to aggressive media should be individually tested for your application. Further details on request.

Link to Product

Illustration

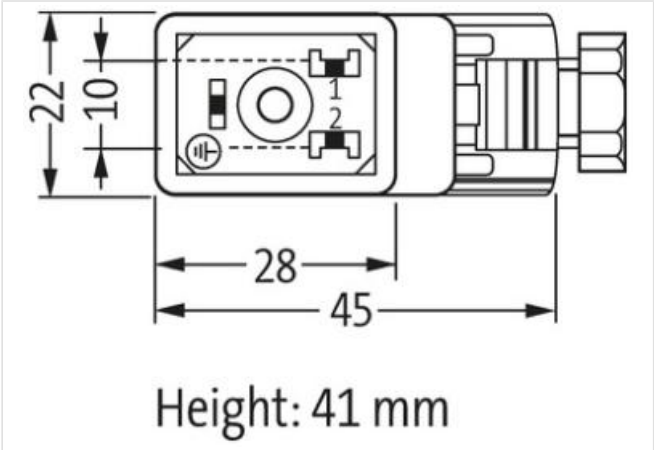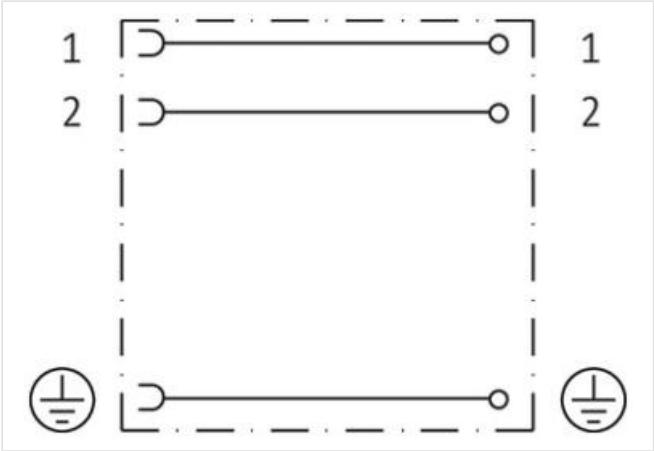

Product may differ from Image

Side 1

Degree of protection (EN IEC 60529) IP65

Commercial data

ECLASS-6.0	27279221
ECLASS-7.0	27440104
ECLASS-8.0	27440104
ECLASS-9.0	27440102
ETIM-5.0	EC002062
customs tariff number	85366990

GTIN	4048879187206
------	---------------

Packaging unit	1
----------------	---

**Electrical data | Supply**

Operating voltage AC max.	230 V
---------------------------	-------

Operating voltage DC max.	230 V
---------------------------	-------

Current operating per contact max.	10 A
------------------------------------	------

**Installation**

Connection cross section max.	1,5 mm <sup>2</sup>
-------------------------------	---------------------

**Installation | Connection**

Tightening torque	0,4 Nm
-------------------	--------

Mounting set	M3
--------------	----

**Device protection | Electrical**

Additional condition protection degree	inserted, locked, with screw connection
--	---

**Mechanical data | Mounting data**

Mounting method	PG9
-----------------	-----

Clamping range min.	6 mm
---------------------	------

Clamping range max.	8 mm
---------------------	------

**Environmental characteristics | Climatic**

Operating temperature min.	-20 °C
----------------------------	--------

Operating temperature max.	60 °C
----------------------------	-------