
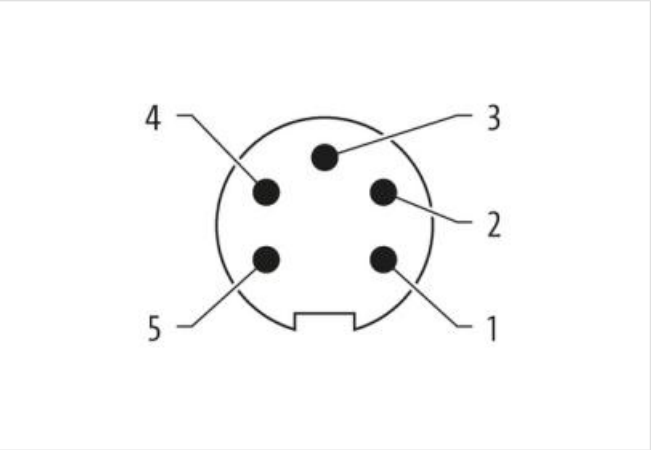


7/8" MALE 0° BUS-FERRULE RESISTOR

Terminating resistor
Male
7/8" (5-pole)
screw fixing
Plastic housings with good resistance against chemicals and oils.
The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)

Illustration

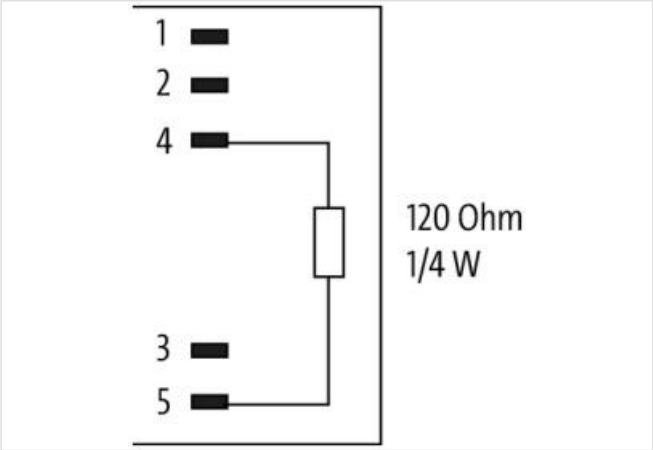

Product may differ from Image



Commercial data	
ECLASS-6.0	27279218
ECLASS-7.0	27279218
ECLASS-8.0	27279218
ECLASS-9.0	27060311
ETIM-5.0	EC001855
customs tariff number	85332900

GTIN	4048879134699
------	---------------

Packaging unit	1
----------------	---

Electrical data | Supply

Current operating per contact max.	8 A
------------------------------------	-----

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP67
-------------------------------------	------

Additional condition protection degree	inserted, screwed
--	-------------------

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
----------------------------	--------

Operating temperature max.	80 °C
----------------------------	-------