


Velcro base including velcro for direct mounting

Clamping range 4-20mm, width 10mm, length 150mm

Base with hook and loop fastener for direct mounting
mounting with M4 countersunk screw (not included in the delivery)

[Link to Product](#)

Illustration

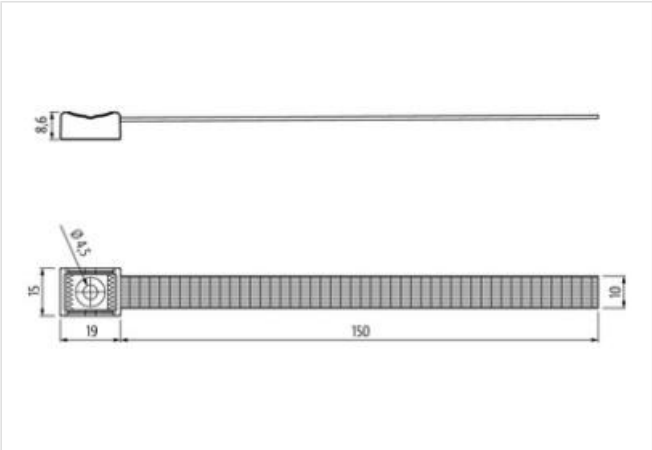

Product may differ from Image



Commercial data	
ECLASS-6.0	27279221
ECLASS-7.0	27440104
ECLASS-8.0	27440104
ECLASS-9.0	27440102
ECLASS-10.1	27140706
ECLASS-11.1	27140706

ECLASS-12.0	27140706
ETIM-5.0	EC002635
customs tariff number	63079098
GTIN	4065909027707
Packaging unit	10

Mechanical data | Material data

Combustibility class (UL94)	V-0
Material housing	PA

Mechanical data | Mounting data

Clamping range min.	4 mm
Clamping range max.	20 mm
Height	169 mm
Width	15 mm
Depth	8,6 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C