

Velcro base including velcro for direct mounting

Clamping range 8-35mm, width 20mm, length 180mm


Base with hook and loop fastener for direct mounting

mounting with M4 or M5 countersunk screw (not included in the delivery)

mounting with M4 or M5 countersunk screw

Link to Product

Illustration

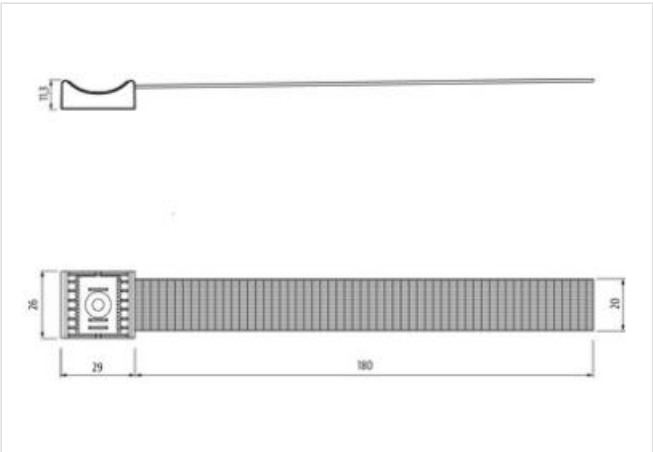

Product may differ from Image



Commercial data	
ECLASS-6.0	27279221
ECLASS-6.1	27140706
ECLASS-7.0	27140706
ECLASS-8.0	27140706
ECLASS-9.0	27140706
ECLASS-10.1	27140706

ECLASS-11.1	27140706
ECLASS-12.0	27140706
ETIM-5.0	EC002635
customs tariff number	63079098
GTIN	4065909028018
Packaging unit	10

Mechanical data | Material data

Combustibility class (UL94)	V-0
Material housing	PA

Mechanical data | Mounting data

Clamping range min.	8 mm
Clamping range max.	35 mm
Height	209 mm
Width	26 mm
Depth	11,3 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C