

Velcro base including velcro for ITEM-profiles

Clamping range 4-20mm, width 10mm, length 150mm


Simple, tool-free mounting in common aluminium profiles
45° rotation allows cable fastening across or parallel to the profile

Link to Product

Illustration



Product may differ from Image

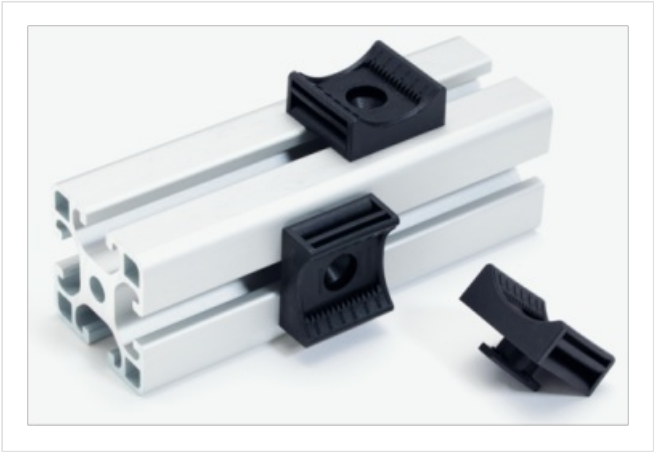

Commercial data	
ECLASS-6.0	27279221
ECLASS-7.0	27140706
ECLASS-8.0	27140706
ECLASS-9.0	27140706
ECLASS-10.1	27140706
ECLASS-11.1	27140706

ECLASS-12.0	27140706
ETIM-5.0	EC002635
customs tariff number	63079098
GTIN	4065909080665
Packaging unit	10

Mechanical data | Material data

Combustibility class (UL94)	V-0
Material housing	PA

Mechanical data | Mounting data

Clamping range min.	10 mm
Clamping range max.	60 mm
Width	20 mm