

MQ15-X-Power female crimp contact 2,5mm²


MQ15  
Crimp  
Female

Link to Product

Illustration



Product may differ from Image

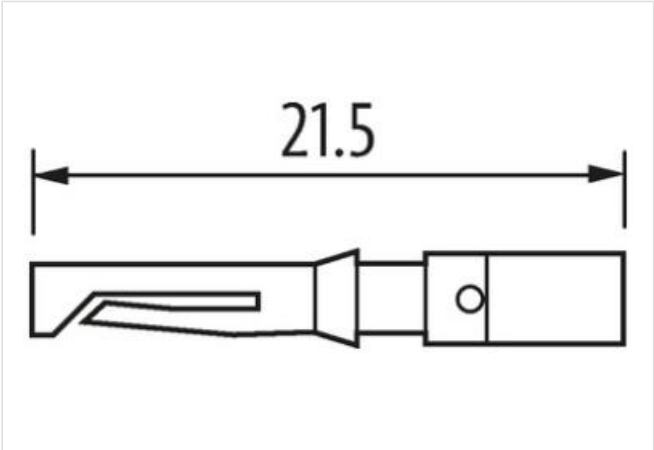

Side 1

Material contact                      Copper alloy

Commercial data

ECLASS-6.0	27279218
ECLASS-6.1	27261202
ECLASS-7.0	27440204
ECLASS-8.0	27440204
ECLASS-9.0	27440204
ECLASS-10.1	27440204
ECLASS-11.1	27440204
ECLASS-12.0	27440204
ETIM-5.0	EC001855
customs tariff number	85366990
GTIN	4048879914826
Packaging unit	100

Electrical data | Supply

Current operating per contact max.                      16 A

Installation

Connection cross section max.                      2,5 mm²

Installation | Connection

Connection	Crimp
Mating cycles min.	500

Mechanical data | Material data

Coating contact                      gold plated

Important installation notes

Note on strain relief	Protect the connectors by suitable measures from mechanical loads, e.g. by the usage of cable ties.
-----------------------	---

Note on bending radius

**Attention:** Observe the permissible bending radii when laying cables, as the IP protection class can be endangered by excessive bending forces.