


B6 Hood, IP68

Screw locking, side entry M32

B6
Hood
Screw locking
IP68
Technical data will be only guaranteed with Murrelektronik components.

Link to Product

Illustration

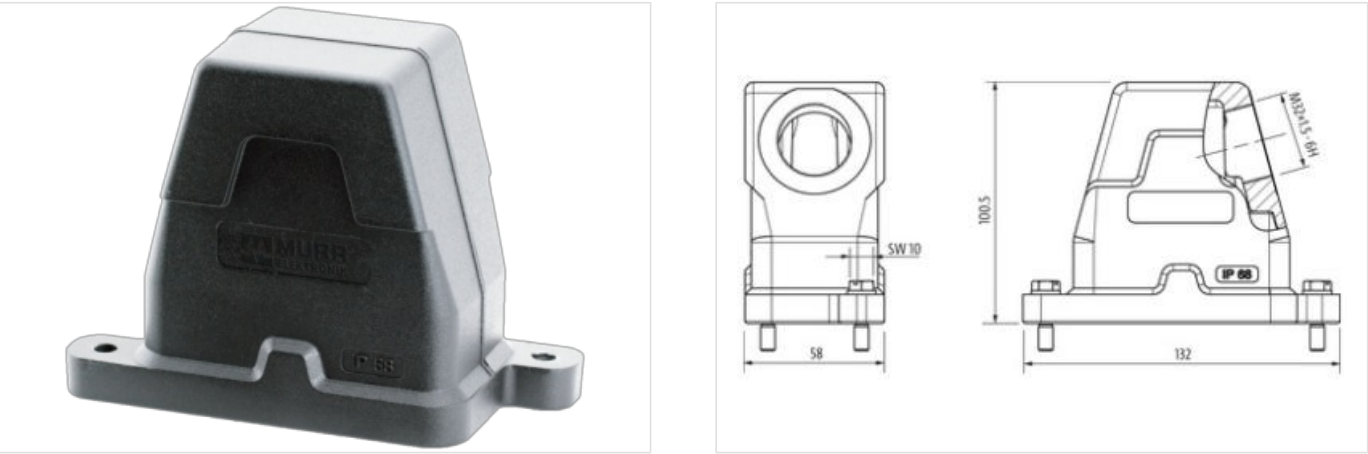

Product may differ from Image

Commercial data

ECLASS-6.0	27143424
ECLASS-6.1	27261203
ECLASS-7.0	27440202
ECLASS-8.0	27440202
ECLASS-9.0	27440202
ECLASS-10.1	27440202
ECLASS-11.1	27440202
ECLASS-12.0	27440202
ETIM-5.0	EC000437
customs tariff number	85389099
GTIN	4048879647359
Packaging unit	1

Installation

Cable outlet	laterally
--------------	-----------

Installation | Connection

Tightening torque	4 Nm
Mounting set	M32
Mating cycles min.	500

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP68
Additional condition protection degree	inserted, locked, with screw connection

Mechanical data

Housing type	Hood
--------------	------

Mechanical data Material data	
Coating housing	powder-coated
Material gasket	Silicon
Material housing	Aluminum die casting
Locking material	Stainless steel
Mechanical data Mounting data	
Size	B6
Mounting method	Screw locking
Height	100,5 mm
Width	58 mm
Depth	132 mm
Environmental characteristics Climatic	
Operating temperature min.	-40 °C
Operating temperature max.	125 °C
Climatic category (EN IEC 60068-1)	40/125/21