

UNIVERSAL CONTACTOR SUPPRESSOR

RC, 48VDC/15VA/W



48 V AC/DC

RC

For other configurations and voltages, please inquire.

Link do produto

Ilustração

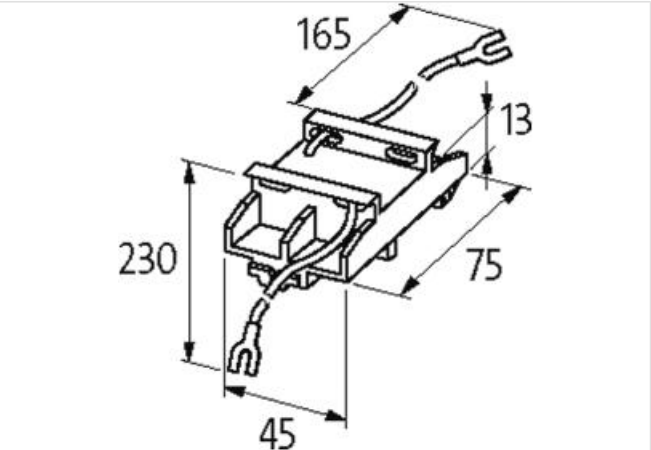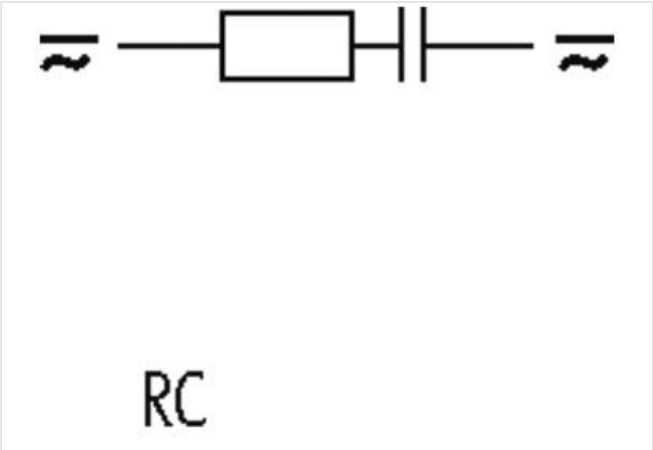

Produto pode diferir da imagem



Dados comerciais	
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013

ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC002498
Classificação fiscal	85363010
GTIN	4048879020466
Quantidade por embalagem	1
Compatibility Compatible with	
Appropriate contactors	universal
Electrical data	
Damping factor	1.5× UN
Holding power max.	15 W
Electrical data Input	
Input voltage AC min.	12 V
Input voltage AC max.	53 V
Input voltage DC min.	12 V
Input voltage DC max.	53 V
Installation Connection	
Connection information	self-securing cable forks
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Combustibility class housing (UL94)	V-0
Material housing	Plastic
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	45 mm
Width	75 mm
Depth	13 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	70 °C