

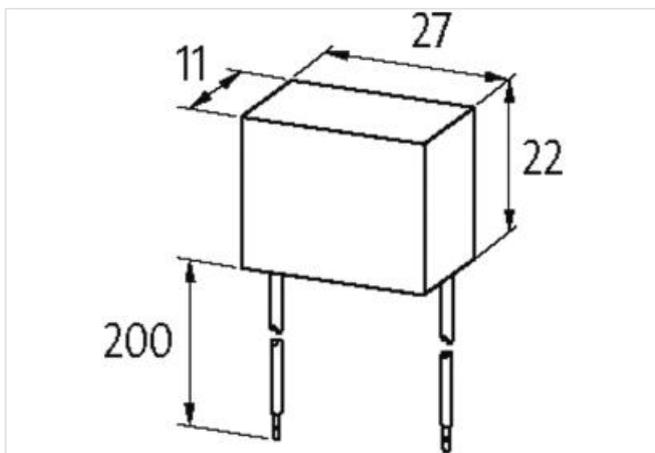
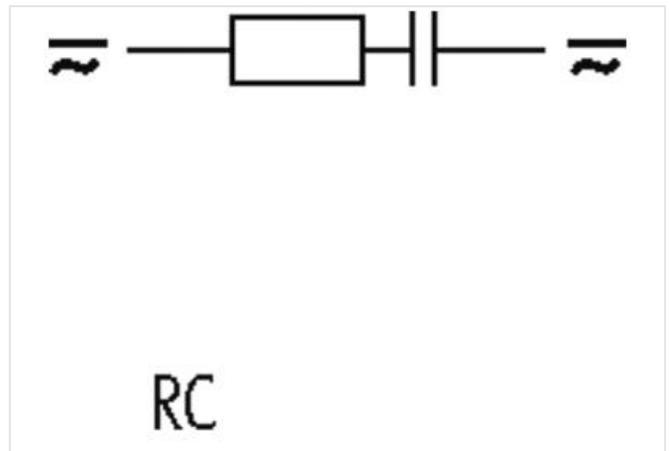
SUPPRESSOR FOR CONTACTORS

RC, 24 VAC/DC, 20 VA/W

24 V AC/DC

RC

For other configurations and voltages, please inquire.

[Link do produto](#)**Ilustração**

Produto pode diferir da imagem

**Dados comerciais**

ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013

ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC002498
Classificação fiscal	85363010
GTIN	4048879020367
Quantidade por embalagem	1

Compatibility | Compatible with

Appropriate contactors	universal
------------------------	-----------

Electrical data

Damping factor	1.5x UN
Holding power max.	20 W

Electrical data | Input

Input voltage AC min.	12 V
Input voltage AC max.	30 V
Input voltage DC min.	12 V
Input voltage DC max.	30 V

Installation | Connection

Connection information	flexible connection wires
------------------------	---------------------------

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Combustibility class housing (UL94)	V-0
Material housing	Plastic

Mechanical data | Mounting data

Height	22 mm
Width	27 mm
Depth	11 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C