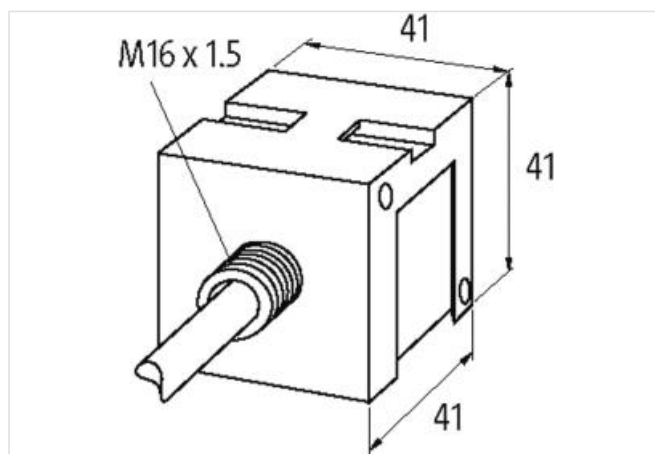
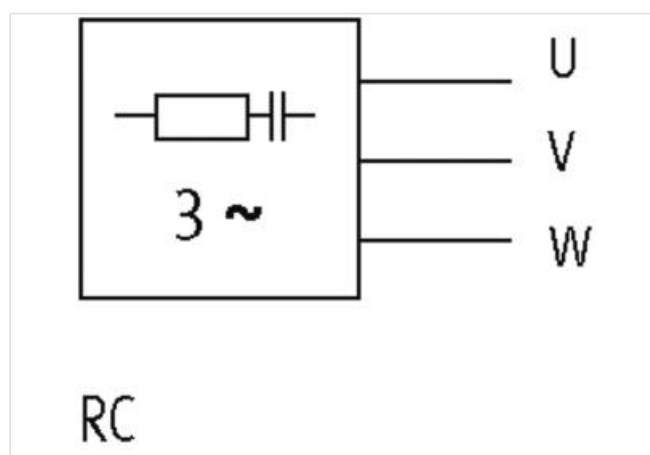


MOTOR SUPPRESSOR

RC, 3x575VAC/7,5kW

RC
 PG9
 3x 575 V AC
 Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.
 For DIN-rail mounting use 2xArt.-No. 20900 adapter feet
 approx. 500 mm, PVC cable 3x 0.75 mm²

Link do produto**Ilustração**

Produto pode diferir da imagem

**Dados comerciais**

ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013

ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC000197
Classificação fiscal	85363010
GTIN	4048879019491
Quantidade por embalagem	1

Electrical data | Supply

Power frequency	50 ... 60 Hz
-----------------	--------------

Electrical data | Input

Input voltage AC	575 V
------------------	-------

Installation

Connection cross section max.	0,75 mm ²
-------------------------------	----------------------

Installation | Connection

Family construction form	free cable end
--------------------------	----------------

Installation | Pin assignment

No. of poles	3
--------------	---

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Combustibility class housing (UL94)	V-0
Material housing	Plastic
Material potting compound	2-component epoxy

Mechanical data | Mounting data

Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, (EN 60715)
Height	41 mm
Width	41 mm
Depth	41 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C