

## MOTOR SUPPRESSOR

Varistor, 3x575VAC/10kW

3 × 575 V AC



VDR

with (M20×1.5 mm) gland

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

### Link do produto

#### Ilustração

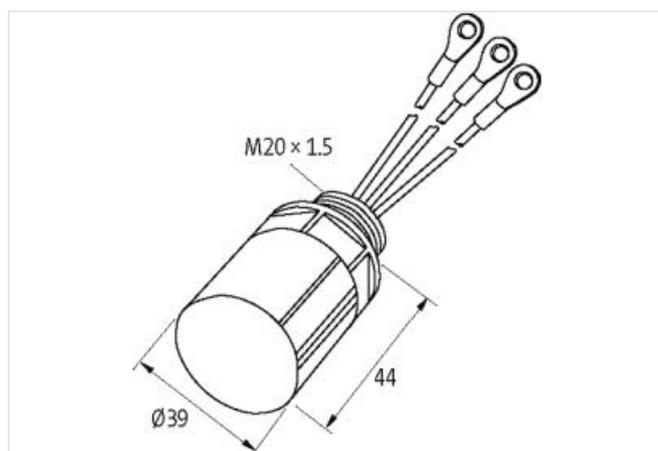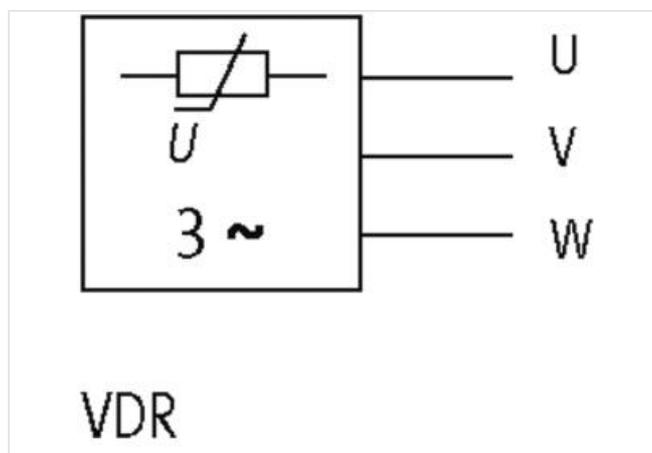

Produto pode diferir da imagem



#### Dados comerciais

ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013

ECLASS-10.1	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC000197
Classificação fiscal	85363010
GTIN	4048879019101
Quantidade por embalagem	1

**Electrical data | Input**

Input voltage AC	575 V
------------------	-------

**Installation**

Connection cross section max.	1 mm <sup>2</sup>
-------------------------------	-------------------

**Installation | Connection**

Connection information	Single strands
Length single strands	150 mm
Ring terminals	M6isolated

**Device protection | Media**

Flame resistance	flame retardant
------------------	-----------------

**Mechanical data | Material data**

Combustibility class housing (UL94)	V-0
Material housing	Plastic
Material potting compound	2-component epoxy

**Mechanical data | Mounting data**

Mounting method	inserted
Suitable for mounting type	Motorklemmkasten
Height	39 mm
Width	39 mm
Depth	44 mm

**Environmental characteristics | Climatic**

Operating temperature min.	-20 °C
Operating temperature max.	60 °C