

**MOTOR SUPPRESSOR**

RC, 3x575VAC/5,5kW



3x 575 V AC

RC

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

[Link do produto](#)

**Ilustração**

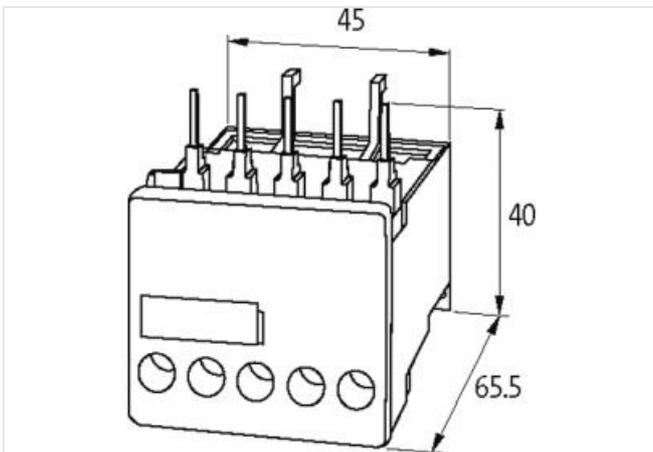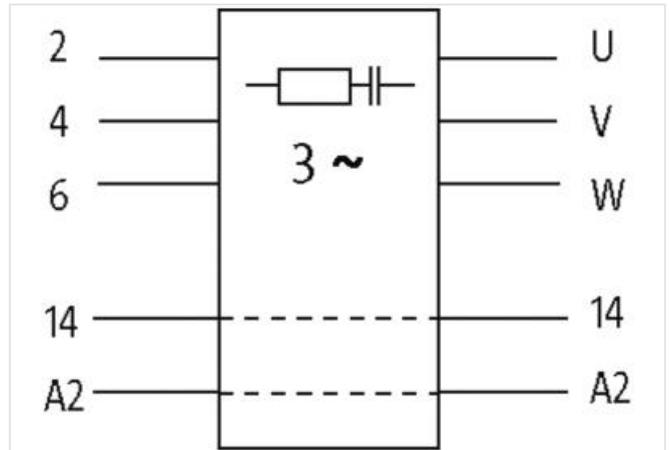

Produto pode diferir da imagem



**Dados comerciais**

|             |          |
|-------------|----------|
| ECLASS-6.0  | 27371013 |
| ECLASS-6.1  | 27371013 |
| ECLASS-7.0  | 27371013 |
| ECLASS-8.0  | 27371013 |
| ECLASS-9.0  | 27371013 |
| ECLASS-10.1 | 27371013 |

As informações contidas nesta folha de dados foram elaboradas com o máximo cuidado. A falta de integridade, exatidão e atualização das informações é considerada negligência grave. versão: 03/05/2024

|   |   |
|---|---|
| ECLASS-11.1                                     | 27371013                                      |
| ECLASS-12.0                                     | 27371013                                      |
| ETIM-5.0  | EC000197                                      |
| Classificação fiscal                            | 85363010                                      |
| GTIN  | 4048879018869                                 |
| Quantidade por embalagem                        | 1   |
| <b>Compatibility   Compatible with</b>          |   |
| Appropriate contactors                          | 3 RT 20, Siemens 3 RT 10                      |
| <b>Electrical data   Supply</b>                 |   |
| Power frequency                                 | 50 ... 60 Hz                                  |
| <b>Electrical data   Input</b>                  |   |
| Input voltage AC                                | 575 V   |
| <b>Installation   Connection</b>                |   |
| Connection information                          | fits directly into SIRIUS contactors, size 00 |
| <b>Device protection   Media</b>                |   |
| Flame resistance                                | flame retardant                               |
| <b>Mechanical data   Material data</b>          |   |
| Combustibility class housing (UL94)             | V-0   |
| Material housing                                | Plastic                                       |
| <b>Mechanical data   Mounting data</b>          |   |
| Height  | 40 mm   |
| Width   | 45 mm   |
| Depth   | 65,5 mm                                       |
| <b>Environmental characteristics   Climatic</b> |   |
| Operating temperature min.                      | -20 °C  |
| Operating temperature max.                      | 60 °C   |