

SIEMENS CONTACTOR SUPPRESSOR

Zener diode, 24VDC



24 V DC

Diode/Z-Diode

For other configurations and voltages, please inquire.

[Link do produto](#)

Ilustração

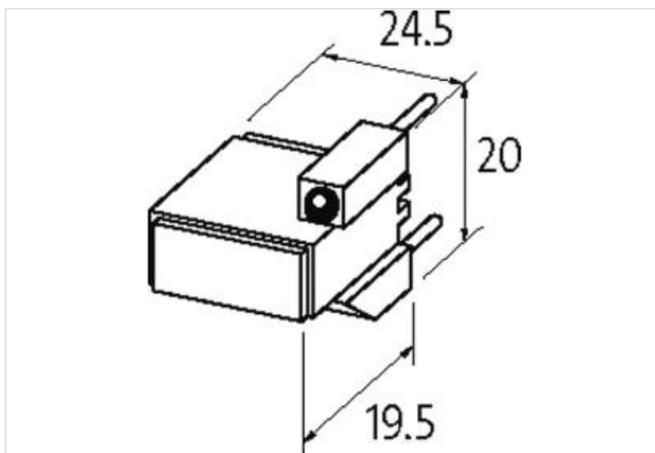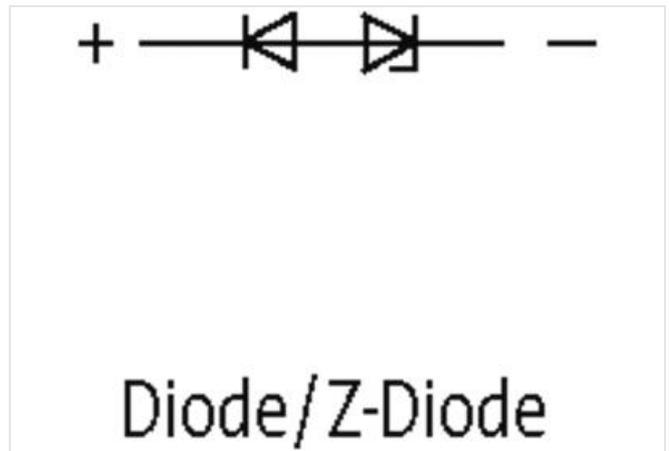

Produto pode diferir da imagem



Dados comerciais

ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013

ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC002498
Classificação fiscal	85363010
GTIN	4048879018586
Quantidade por embalagem	1

Compatibility | Compatible with

Appropriate contactors	3 TH 2; 3 TF 2; 3 TH 20; 3 TF 20
------------------------	----------------------------------

Electrical data

Damping factor	1.5x UN
----------------	---------

Electrical data | Input

Input voltage DC min.	24 V
Input voltage DC max.	240 V

Installation | Connection

Connection information	Plug contact
------------------------	--------------

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Combustibility class housing (UL94)	V-0
Material housing	Plastic

Mechanical data | Mounting data

Height	19,5 mm
Width	20 mm
Depth	24,5 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C