




**POWER DISTRIBUTOR PD4 7/8" 5 POLE**

24+E male to 4 x 7/8" 5-pole female

Industry male plug 24+PE  
to 4 x 7/8" UNF female  
5-pole

[Link do produto](#)

**Ilustração**

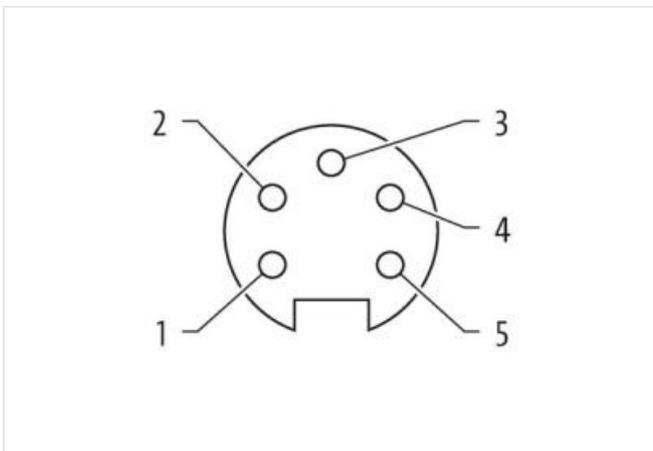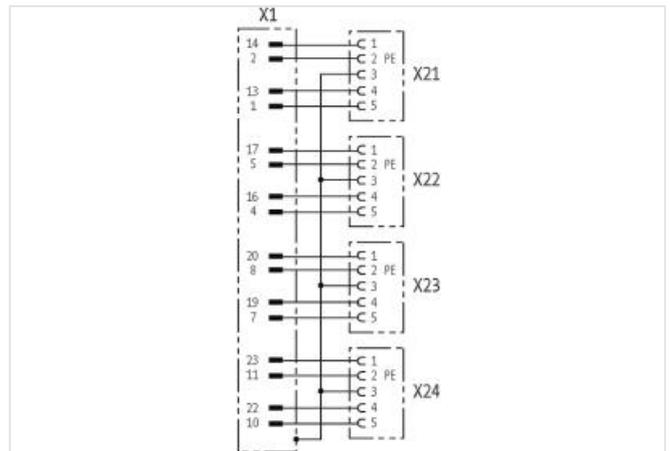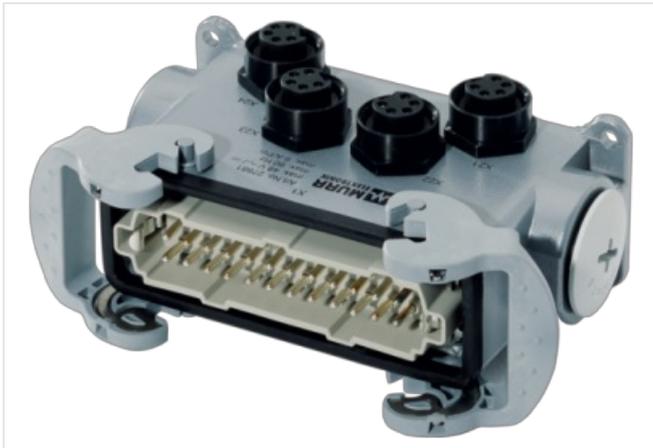

Produto pode diferir da imagem



**Dados comerciais**

ECLASS-6.0	27279219
ECLASS-6.1	27142601
ECLASS-7.0	27142601
ECLASS-8.0	27142601
ECLASS-9.0	27142601
ECLASS-10.1	27142601

ECLASS-11.1	27142606
ECLASS-12.0	27142606
ETIM-5.0	EC002585
Classificação fiscal	85369010
GTIN	4048879063449
Quantidade por embalagem	1

**Electrical data**

Security level	SELV
----------------	------

**Electrical data | Supply**

Operating voltage AC	50 V
Operating voltage DC	120 V
Current operating per contact max.	9 A

**Device protection | Electrical**

Degree of protection (EN IEC 60529)	IP67
Additional condition protection degree	inserted, screwed

**Mechanical data | Material data**

Coating housing	powder-coated
Material housing	Aluminum die casting

**Mechanical data | Mounting data**

Height	165 mm
Width	70 mm
Depth	100 mm
Looking techniques	2-hand fixing (2 clamps)

**Environmental characteristics | Climatic**

Operating temperature min.	-30 °C
Operating temperature max.	85 °C