



EMMDS 30-64/0,1 OPTO-COUPLER MODULE

IN: 230 VAC - OUT: 40 VDC / 0,1 A

Transistor 0.1 A
230 V AC
Double terminals on the output side

Link do produto

Ilustração

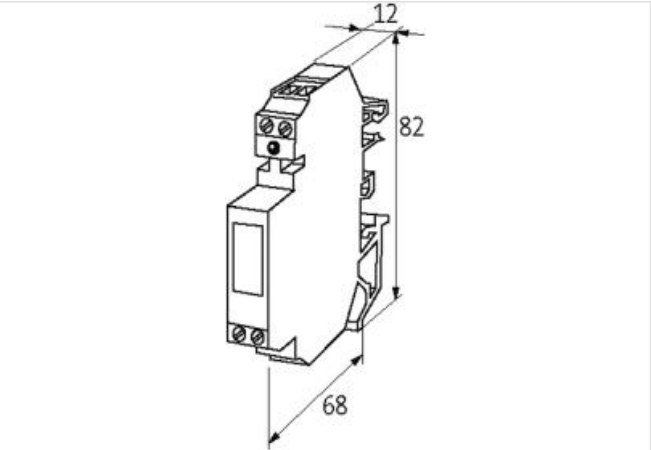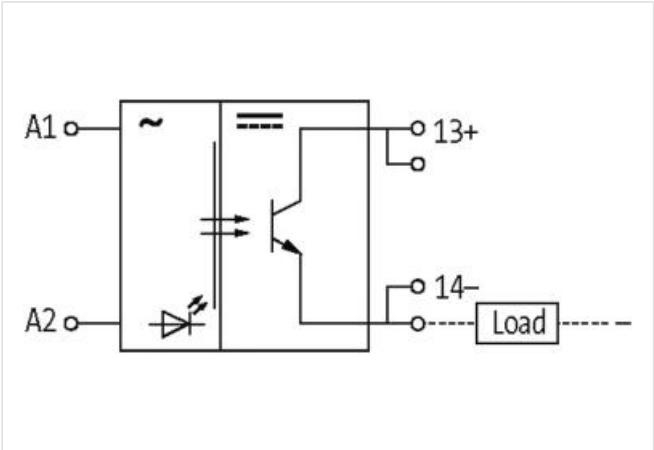

Produto pode diferir da imagem



Dados comerciais	
ECLASS-6.0	27371604
ECLASS-6.1	27371604
ECLASS-7.0	27371604
ECLASS-8.0	27371604
ECLASS-9.0	27371604
ECLASS-10.1	27371604

ECLASS-11.1	27371604
ECLASS-12.0	27371604
ETIM-5.0	EC001504
Classificação fiscal	85414900
GTIN	4048879027939
Quantidade por embalagem	1
Electrical data Input	
Input voltage AC min.	195 V
Input voltage AC max.	253 V
Input voltage OFF AC min.	0 V
Input voltage OFF AC max.	110 V
Input current	7,5 mA
Electrical data Output	
Switch off delay max.	120 ms
Switch on delay max.	50 ms
Quiescent current OFF max.	0,3 mA
Switching frequency inductive max.	1 Hz
Switching frequency ohmic max.	10 Hz
Voltage switching DC min.	4 V
Switching voltage DC max.	40 V
Switching current min.	1 mA
Switching current max.	0,1 A
Voltage drop DC max.	1,2 V
Diagnostics	
Status indication LED	red
Device protection Electrical	
Rated insulation voltage	3750 V
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Color housing	black
Material housing	Plastic
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, G32, (EN 60715)
Height	82 mm
Width	12 mm
Depth	64 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C